

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Suitable for emergency lighting applications such as stairways and hallways.

CONSTRUCTION

Injection-molded, flame-retardant, high-impact, thermoplastic housing with snap-fit design components with LED lamps for easy installation. Universal J-box pattern. Track and swivel arrangement permits full range of lamp adjustment. Not intended for ceiling mounting.

OPTICS

The typical life of the LED is 10 years. Two 1.8W LED lamps for emergency light.

ELECTRICAL

Dual-voltage input 120V or 277V AC. Emergency unit provided with test switch, status indicator and rechargeable battery. Maintenance-free nickel-cadmium battery provides 90 minutes of emergency power.

LISTINGS

UL Listed. Meets UL 924, NFPA 101, NFPA 70-NEC and OSHA illumination standards. Damp location 32°F to 122°F (0°C to 50°C) listed standard.

WARRANTY

Fixtures are covered by Lithonia Lighting 24-month warranty against mechanical defects in manufacture.

All life safety equipment, including emergency lighting for path of egress must be maintained, serviced, and tested in accordance with all National Fire Protection Association (NFPA) and local codes. Failure to perform the required maintenance, service, or testing could jeopardize the safety of occupants and will void all warranties.


Note: Specifications subject to change without notice.

Actual performance may differ as a result of end-user environment and application.

Contractor Select

LED UNITS

LED Lamps

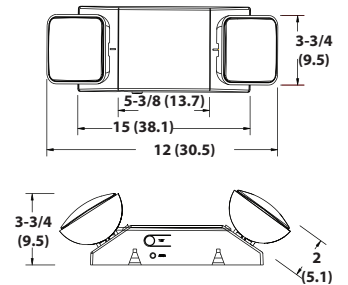

All dimensions are inches (centimeters) unless otherwise indicated.

ORDERING INFORMATION

Catalog Number	UPC	Description	Supply Voltage	Input Wattage ¹	Standard Pallet Qty.	Carton Qty.
EU2 LED M12	784231874493	Emergency lighting unit	120/277	1.8	324	12

Accessories: Order as separate items.	
ELA WG1	Wireguard (back mount only) ²

Notes:

- Per lamp head.
- See spec sheet [ELA-WG](#).

