



# LOUISVILLE®

LADDERS TRUSTED BY THE PROS FOR OVER 65 YEARS

## MULTI PURPOSE LADDER

### Échelle multifonction Escalera multiposición


**300** lbs. **TYPE IA**  
load capacity\*  
\*includes weight of user plus materials

Type IA: 136 kg Capacité de charge  
Tipo IA: 136 kg Capacidad de carga

- Easy operation with lightweight aluminum design  
French | De construcción ligera y fácil de operar
- Wider footprint provides more stability  
French | Amplia superficie de pisada brinda mayor estabilidad
- Easy-to-use flip & lock hinges  
French | Mecanismo de bloqueo y ensamble ergonómico

# 5 LADDERS IN ONE!

Échelles dans un | Escaleras en una

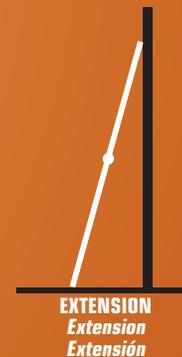

TRILINGUAL L-2095 MP FLYER 2014 v1 © 2014 Louisville Ladder, Inc. All rights reserved.



MODEL MODÈLE MODELO	LADDER SIZE HAUTEUR DE L'ÉCHELLE TAMAÑO ft. (m)	ADJUSTABLE STEPLADDER ESCABEAU TIJERA AJUSTABLE ft. (m)	STAIRWAY ESCALIER A DESNIVEL ft. (m)	SCAFFOLD ÉCHAFAUDAGE PLATAFORMA PARA ANDAMIO ft. (m)	STRAIGHT / EXTENSION EXTENSION RECTA / EXTENSIÓN ft. (m)	APPROX. WT. POIDS APPROXIMATIF PESO APROX. lbs. (kgs)	APPROX. CUBES VOLUME APPROXIMATIF VOLUMEN APROX. ft. (m <sup>3</sup> )
L-2095-13	13' (4)	3 - 5 (0.9 - 1.5)	3 - 5 (0.9 - 1.5)	1 - 2 (0.3 - 0.6)	7 - 11 (2.1 - 3.4)	23.8 (10.8)	4.2 (0.1)
L-2095-17	17' (5.2)	4 - 7 (1.2 - 2.1)	4 - 7 (1.2 - 2.1)	1 - 3 (0.3 - 0.9)	9 - 15 (2.7 - 4.6)	29.3 (13.3)	6.1 (0.2)
L-2095-22	22' (6.7)	5 - 9 (1.5 - 2.7)	5 - 9 (1.5 - 2.7)	1 - 4 (0.3 - 1.2)	11 - 19 (3.4 - 5.8)	34.7 (15.7)	8.9 (0.3)



www.LouisvilleLadder.com | 1-800-666-2811