


NOTES:

- ① This product is designed to meet the National Electric and is ETL Listed for the US and Canada, bear the CE mark and ETL Sanitation Listed tested to NSF/ANS 37 Standards.
- ② Continuous duty, direct drive, variable speed, double shaft motors with automatic thermal overload protection. Overload protects motor from burnout, minimizing maintenance costs. Unit supplied with an 8' cord, three conductor cord and plug.
- ③ Blower wheels are rust proof and dynamically balanced to provide quiet operation, while maintaining high air velocity.
- ④ Low profile appearance. Overall height is 8" and overall depth is 8 7/8".
- ⑤ Air directional vanes, with 40° sweep front to back, compensates for drafts.
- ⑥ Countertop or concession applications are denoted with an-F at after voltage and supplied with washable aluminum filters. LPN225 includes the washable aluminum filters as standard. be located on the right hand unit and controls both units.
- ⑦ All units have a self contained one piece cabinet, fire retardant and corrosion proof paint lock metal double protected with baked on Obsidian Black color, rust preventative electrostatic polyurethane powder coating.
- ⑧ Normally closed door limit switch(es) is optional and field installed. Switch to be mounted so the air curtain turns on as the door begins to open.



*1/2" BEARING CAPS USED

MODEL NUMBER	UNIT LENGTH (A)
LPN225-1U*	26"
LPN236-1U	36"
LPN242-1U	42"
LPN248-1U	48"
LPN260-1U	60"
LPN272-1U	72"
LPN284-2U	86"
LPN296-2U	98"
LPN2108-2U	110"
LPN2120-2U	122"
LPN2144-2U	146"

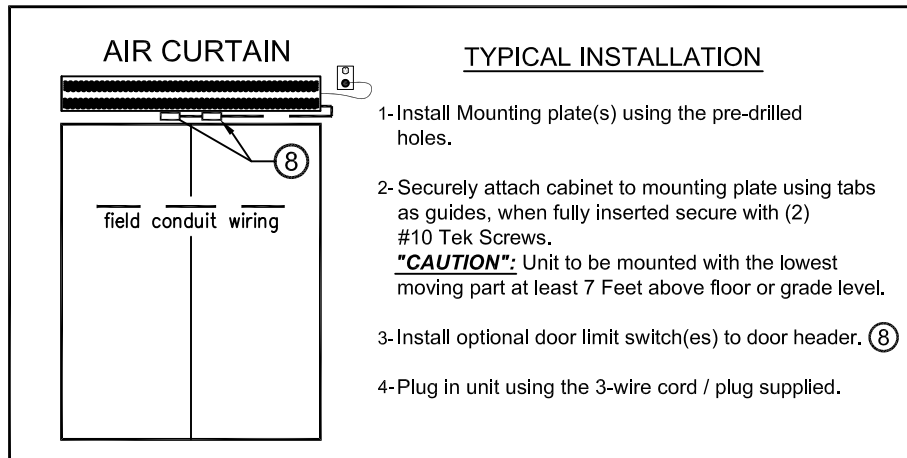

PROJECT	Model No.:
LOCATION	Drawing No.:
ARCHITECT	Date
ENGINEER	Sheet of
	Drawn By:
	Checked By:



14716 S. Broadway • Gardena, CA 90248 • USA
 TEL:(310) 532-1555 • (800) 421-1266 • FAX:(310) 324-3030
 Web Site: www.marsair.com • E-mail:info@marsair.com

JOB:

ARCHITECT/ENGINEER:

DRWG.: _____

CONTRACTOR:

SHEET _____ **of** _____ **DATE:** _____

MARK	MODEL NUMBER	NUMBER REQ'D	OVERALL LENGTH (INCHES)	MOTOR HP @ 1550 RPM**	WEIGHT (LBS)	MOTOR FAN DATA					REMARKS
						FLA* SINGLE PHASE		Max FPM** at Nozzle	Max CFM** at Nozzle	dBA Measured 10 ft. from Nozzle	
						115V	208/230V				
	LPN225-1U		26	1 @ 1/6	20	2.4	1.2/1.2	1800	625	49	
	LPN236-1U		36	1 @ 1/6	32	2.4	1.2/1.2	1800	900	49	
	LPN242-1U		42	1 @ 1/6	35	2.4	1.2/1.2	1800	1050	50	
	LPN248-1U		48	1 @ 1/6	40	2.4	1.2/1.2	1800	1200	52	
	LPN260-1U		60	1 @ 1/6	48	2.6	1.4/1.4	1800	1500	53	
	LPN272-1U		72	1 @ 1/6	58	2.6	1.4/1.4	1800	1800	53	
	LPN284-2U		86	2 @ 1/6	75	4.8	2.4/2.4	1800	2100	53	
	LPN296-2U		98	2 @ 1/6	83	4.8	2.4/2.4	1800	2400	53	
	LPN2108-2U		110	2 @ 1/6	92	5.0	2.6/2.6	1800	2700	54	
	LPN2120-2U		122	2 @ 1/6	102	5.2	2.8/2.8	1800	3000	54	
	LPN2144-2U		146	2 @ 1/6	122	5.2	2.8/2.8	1800	3600	54	

EQUIPMENT SPECIFICATIONS – Standard Features

GENERAL

Air curtain shall be a Mars® Air Systems brand air curtain: LoPro2 ETL Sanitation Listed Commercial unheated.

APPROVALS

Air curtain shall meet the requirements of the National Electric Code. (N.E.C.), ETL Listed for US & Canada, bear the CE mark and ETL Sanitation listed per NSF/ANSI 37 Standard.

CABINET

Cabinet shall be a self contained one piece housing with sufficient strength for fastening to wall on both ends without intermediate support. Cabinet constructed of fire retardant, corrosion proof paint lock metal double protected with baked on Obsidian Black color, rust preventative electrostatic polyurethane powder coating. Discharge air outlet nozzle is internal wedge shaped containing adjustable air direction aluminum vanes with 40° sweep front to back. Motor & Fans are easily accessible for maintenance.

MOTORS AND BLOWER WHEELS

Motor(s) shall be totally enclosed air over (TEAO) type suitable for continuous heavy duty, all angle operation. Construction shall include sealed lifetime pre-lubricated ball bearings, resilient mounted and protected by an automatic reset thermal overload switch. Motor(s) to have double extended shaft and direct drive, cross flow blower wheels.

ELECTRICAL WIRING

Unit supplied with 1/2" Conduit Knockouts.

GUARANTEE

Shall be 5 years on all parts.

ACCESSORIES


Refer to optional features and accessories page.

*- For Ampacity Multiply FLA X 1.25

** - 17% Reduction in Performance on units with 50Hz.

EXAMPLE

LPN2144-2U A-OB

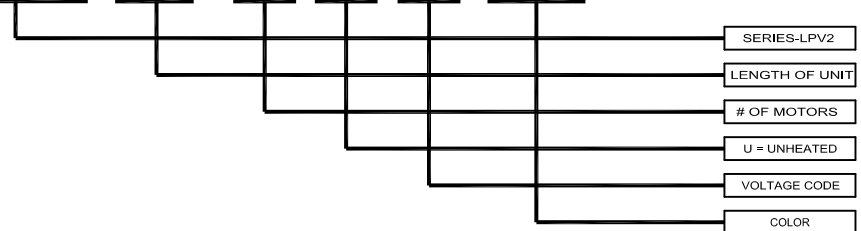

SIZE	VOLTAGE	CODE
25"-144"	115/1/60	A
25"-144"	208-230/1/60	D
25"-144"	220/1/50	U

COLOR	CODE
OBSIDIAN BLACK	OB
TITANIUM SILVER	TS
PEARL WHITE	PW
SPARTAN BRONZE	SB
BATTLESHIP GRAY	BG

MADE WITH PRIDE IN THE U.S.A.