

NEW

Milwaukee[®]

M18 FUEL™

DRIVEN TO OUTPERFORM.™



UP TO
750 FT-LBS
MAX FASTENING
TORQUE

UP TO
1200 FT-LBS
NUT-BUSTING
TORQUE

UP TO
2X
MORE
RUN-TIME

**3/4" High Torque Impact
Wrench with Friction Ring**

22UT69

**REDLITHIUM™
XC4.0**

3/4" HIGH TORQUE IMPACT WRENCH WITH FRICTION RING

M18 FUEL

UP TO
750 FT.-LBS
MAX FASTENING
TORQUE

UP TO
1200 FT.-LBS
NUT-BUSTING
TORQUE

UP TO
2X
MORE
RUN-TIME




M18 FUEL™ 22UT69 vs COMPETITORS

	Milwaukee®	Milwaukee®	Competitor 1	Competitor 2
				
	22UT69	4LET5		
Motor	POWERSTATE™ Brushless	4-Pole Neo	2-Pole Ferrite	2-Pole Ferrite
Max Fastening Torque	750 ft.-lbs.	525 ft.-lbs.	345 ft.-lbs.	434 ft.-lbs.
Nut-Busting Torque	1,200 ft.-lbs.	750 ft.-lbs.	345 ft.-lbs.	434 ft.-lbs.
Length	9"	8-7/8"	11-1/4"	15-1/8"
Drive-Control™	Yes	No	No	No
LED Light	Yes	No	No	No
Powered By	REDLITHIUM™ XC4.0	REDLITHIUM™	A/C Cord	A/C Cord

PROPRIETARY 2-MODE DRIVE CONTROL™

22UT69	MODE 1	MODE 2
No Load Speed (RPM / IPM)	0 – 1,200 / 0 – 1,700	0 – 1,700 / 0 – 2,300
Max Fastening Torque	375 ft.-lbs.	750 ft.-lbs.

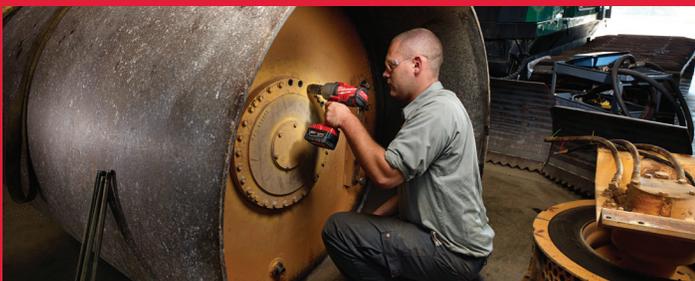

M18 FUEL™ 3/4" High Torque Impact Wrench w/ Friction Ring (Tool-Only) 22UT68

Includes: 2764-20 M18 FUEL™ 3/4" High Torque Impact Wrench w/ Friction Ring



M18 FUEL™ 3/4" High Torque Impact Wrench w/ Friction Ring (Kit - 2 Batteries) 22UT69

Includes: 2764-20 M18 FUEL™ 3/4" High Torque Impact Wrench w/ Friction Ring, (2) M18™ REDLITHIUM™ XC4.0 Extended Capacity Battery Packs, M12™ & M18™ Multi-Voltage Charger, and Carrying Case