



# PRODUCT SALES SHEET

## A00124 Heavy Duty Glass Cleaner

### Cleaning




#### Features

- Nonammoniated Formula
- No Streaking, Hazing, Smearing Or Residue
- Environmentally Preferable Formula
- 360° Valve Allows Can to Spray Upside Down
- Pleasant Lemon Fragrance

#### Description

This versatile, extra strength product is the ONE product for even the toughest glass cleaning applications. Windows, glass, windshields, mirrors, displays, counters and more are easily cleaned of dirt, grease, oil, smudges, fingerprints, lipstick, and other stubborn deposits. The nonammoniated formula is safe on plastics and plexiglass™ and makes an excellent CRT cleaner. It even removes paint overspray, nicotine film and insects when used on vehicles and is safe on window/windshield tinting film. The advanced chemistry provides professional quality cleaning without streaking, smearing, hazing or leaving behind any residue or film. The special formulation is pleasantly fragranced and has a stable foam consistency that breaks quickly and easily when wiped. There is no "pushing around excess foam" yet the optimum economic yield is achieved.

TECHNICAL INFO:		
Physical Properties	Appearance	Foamy Spray
	Color	White
	Odor/Fragrance	Lemon
	pH	9.0-11.0
	Spray Pattern	Wide Oval
Environmental Profile	Glycol Ether Content	Yes (P Series)
	Biodegradability	Yes (Surfactants)
	Chlorinated Solvents	No
	Green Status	None
	Recyclable Packaging	Yes
Regulatory Compliance	% VOC By Weight	9.1
	VOC Restricted Regions	None
	Food Processing Suitability	C1
	EPA #	N/A
	Flammability per CPSC	NCAF
	NFPA Code 30B Storage Level	1

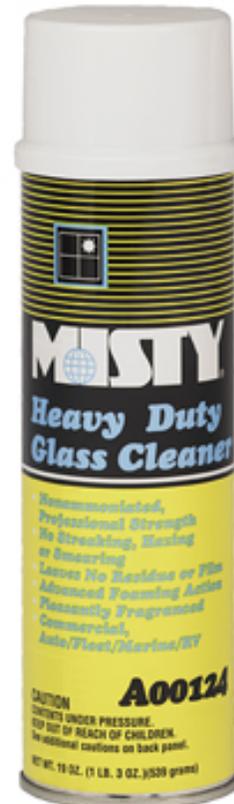

Packages Available:



Label Datecode: 12/08

Manufactured by:



990 Industrial Park Drive • Marietta, GA 30062  
 800-241-7766 • 770-422-2071 • Fax: 770-422-1737  
[www.amrep.com](http://www.amrep.com)