





MOTOR SPECIFICATIONS

| MODEL | VOLT | RPM(load) | IN-LBS | AMP | GRAINGER |
|--------------|------|-----------|--------|-----|----------|
| CEMP-2425-4G | 24 | 8.5 | 50 | 1.0 | 20UH01 |
| CEMP-2425-6G | 24 | 24 | 50 | 1.0 | 20UH02 |

NOTES:

PLASTIC GEARBOX BLACK
 GREASE LUBRICATED GEARS
 BI-DIRECTIONAL
 DO NOT STALL MOTOR
 LIGHT DUTY CYCLE
 RADIAL LOAD NOT TO EXCEED 15LBS

| | | | |
|---------------------------------------|---------|--------------|-------|
| MOLON PART # CEMP-GRANGER-SPECS | | DATE 5/31/13 | |
| DESCRIPTION PRC SHEET # PK-10484-CEMP | | DATE 5/31/13 | |
| CUSTOMER: GRANGER PROPOSAL | | DATE 5/31/13 | |
| SCALE FULL | | DRWN BY SHAY | OK BY |
| LET. | CHANGE | DATE | BY |
| A | RELEASE | 1/121/ | SHAY |
| | | | |
| | | | |
| | | | |
| | | | |
| | | | |
| | | | |

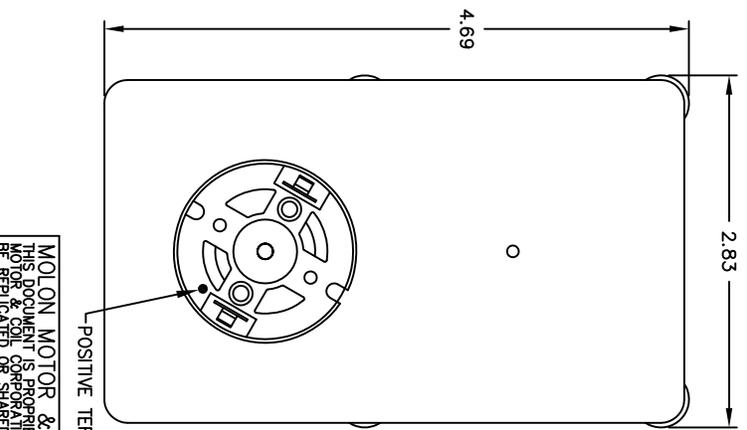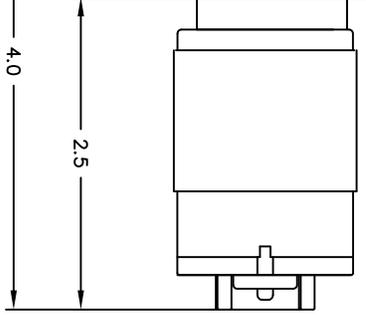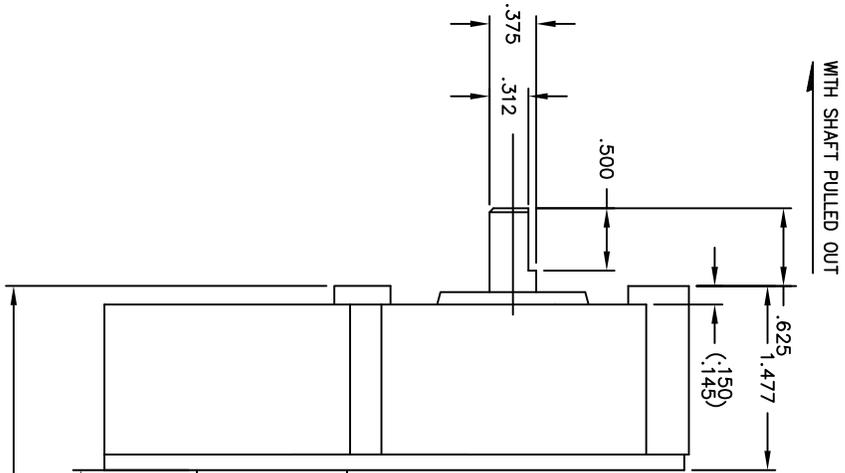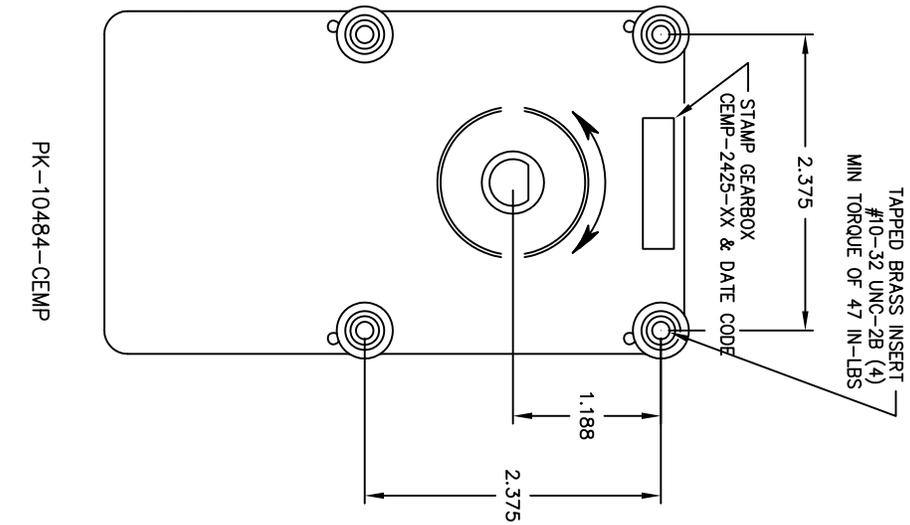

MOLON MOTOR & COIL CORP.
 THIS DOCUMENT IS PROPRIETARY TO MOLON
 MOTOR & COIL CORPORATION AND MAY NOT
 BE REPLICATED OR SHARED.

PK-10484-CEMP