

# NOR-LAKE<sup>®</sup> SCIENTIFIC UNDERCOUNTER & FREE STANDING REFRIGERATOR / FREEZER

**Designed to meet the demanding requirements of scientific and laboratory applications.**

## Standard Product Features:

- Freezer/Refrigerator thermostatic control range adjustable to -20°C freezer, +4°C refrigerator
- Independent internal freezer compartment with door
- Exterior front, door, top and sides are painted white
- Interior liner and interior door panel are white durable vacuum formed poly with seamless rounded corners for easy cleaning
- Cabinet and door are foamed-in-place with CFC-free high density polyurethane foam insulation
- Stackable design with optional stacking kit
- Pull door handle
- Door lock (2 keys)
- 2 adjustable and removable glass shelves
- 1 removable clear plastic drawer bins
- 2 front leveling legs
- 115/60/1 cord and plug
- Base mount refrigeration system
- May be built-in on three sides, air intake and exhaust is through the base, top and rear of the unit
- Compatible with laboratory case work dimensions
- Air-cooled condensing unit
- Manual defrost freezer, auto defrost refrigerator
- Interior light
- Drain pan evaporation
- Magnetic door gasket
- Recessed kickplate
- Reversible door
- Warranty: 12 months parts and labor (US and Canada), 12 months parts (International)
- UL and C-UL listed

## Optional Features:

- Digital thermometer monitor with alarm (field installed, shown below)
- Stacking kit



**Optional Digital Thermometer Monitor With Alarm**



**LRF051WWW/0M**

**NORLAKE<sup>®</sup> SCIENTIFIC**






Committed to our environment



Nor-Lake, Inc.  
Registered to ISO 9001:2008  
File No. 10001816

NOR-LAKE SCIENTIFIC  
A Division of  
NOR-LAKE, INCORPORATED  
727 Second Street  
P.O. Box 248  
Hudson, Wisconsin 54016  
800-477-5253  
715-386-2323  
800-388-5253 PARTS  
715-386-4290 FAX  
[www.norlakescientific.com](http://www.norlakescientific.com)

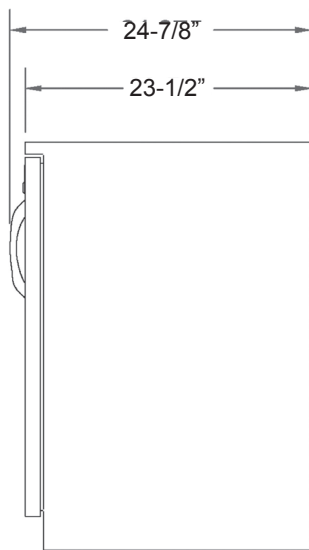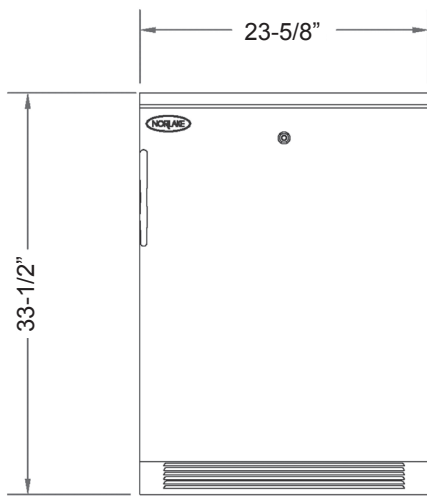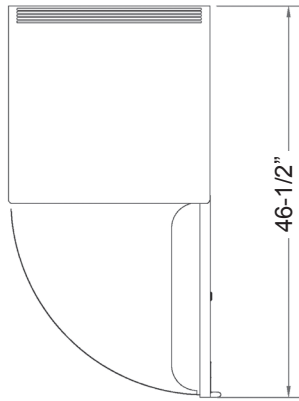

**LRF051WWW/0M Refrigerator/Freezer**

**SPECIFICATIONS**

<b>Model</b>	<b>LRF051WWW/0M</b>
Crated Weight (lbs) (kg)	104 (47)
Crated Height (in) (cm)	39-1/2 (100)
Crated Width (in) (cm)	30 (76)
Crated Depth (in) (cm)	28-1/4 (72)
Interior Height (in) (cm)	24 (61)
Interior Width (in) (cm)	17-1/2 (44)
Interior Depth (in) (cm)	16-1/2 (42)
Overall Height (in) (cm) *	33-1/2 (85)
Overall Width (in) (cm)	23-5/8 (60)
Overall Depth (in) (cm)	24-7/8 (63)
Gross Cubage (CuFt) (L)	4.0 (113)
Freezer (CuFt) (L)	.65 (18)
Refrigerator (CuFt) (L)	3.35 (95)
Number of Shelves	3 - (2 fixed position)
Shelf Area (SqFt) (Sqm)	3.11 (0.29)
Number of Leveling Feet	2
Condensing Unit Size	1/8 HP
Refrigerant	R-134a
Electrical Characteristics	115/60/1
Cord & Plug Furnished	Yes
NEMA Plug Configuration	5-15P
Total Amp Draw	1.3

Specifications subject to change without notice

\* The overall heights shown in the table and drawings are with the levelers installed.

Voltage Model Suffix Code	Voltage Description	NEMA Plug	NEMA Receptacle
/0	115V, 1PH, 60HZ	5-15P	5-15R



Revision Date: 09/13  
 ©2013 NOR-LAKE, INC.  
 Printed in the U.S.A.  
 Part Number: 139483