

Model No.	Size D-L	Wt. Cap.	# Of Hooks	Ship Wt.
-----------	----------	----------	------------	----------

T-BAR WALL SHELF / POT RACK

1121PR.....	20" x 36"	700	6	15#
1122PR.....	20" x 48"	600	7	21#
1123PR.....	20" x 60"	500	8	26#

Adjustable pot rack hooks slide easily into place to fit your needs.

Model No.	Size D-L	Wt. Cap.	Ship Wt.
-----------	----------	----------	----------

T-BAR WALL SHELVES

1121.....	20" x 36"	700	11#
1122.....	20" x 48"	600	14#
1123.....	20" x 60"	500	16#
1124.....	24" x 60"	500	26#

Heavy duty shelf design for larger, heavier product.

SLANTED T-BAR WALL SHELVES

97102.....	21" x 48"	600	26#
------------	-----------	-----	-----

SOLID WALL SHELVES- REGULAR 18 GA

NS675	12" x 24"	200	5#
1125.....	12" x 36"	150	7#
1126.....	12" x 48"	125	8#
1127.....	12" x 60"	100	9#

For lighter loads and smaller product, contains spills.

Options:

Extra Undershelf Brackets - Call Factory

SOLID WALL SHELVES - HEAVY DUTY 12 GA

NS675A	12" x 24"	300	6#
1125A.....	12" x 36"	300	8#
1126A.....	12" x 48"	225	11#
1127A.....	12" x 60"	150	13#
NS753	15" x 24"	300	5#
NS943	15" x 36"	300	7#
NS793	15" x 48"	225	11#
94249.....	15" x 60"	150	12#
95634.....	18" x 24"	300	8#
92093.....	18" x 36"	300	10#
92094.....	18" x 48"	225	13#
94136.....	18" x 60"	150	15#

Thick, 12 gauge for heavier loads. Performs like stainless steel.

OPTIONS:

Extra Undershelf Brackets - Call Factory

MICROWAVE SHELF - HEAVY DUTY 12 GA

95634.....	18" x 24"	300	8#
95883.....	24" x 24"	300	10#

- Lifetime warranty against rust and corrosion.
- NSF Certified

Weight Capacity



• Method of installation and type of wall determine the weight capacity of these shelves.


Wall Shelves



T-Bar Wall Shelf / Pot Rack



T-Bar Wall Shelf

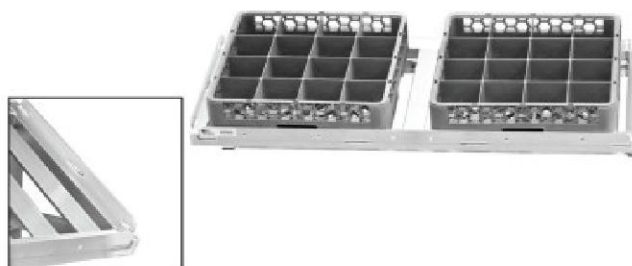

Slanted T-Bar Wall Shelf



Solid Wall Shelf • H.D. & Standard



Microwave Shelf

