



America's Largest Offshore Vehicle Lighting Manufacturer.

BUL10/22/52 Series



6" Oval Sealed Clear DOT LED Back-Up Lights

- Sonically sealed, waterproof
- Certified for back-up light function when installed as pair in two-lamp system [SAE (2)R]
- Low to high diode count; choose from 10-, 27- or 36-LED models
- Accept standard two-pin plugs

- BUL10CB** 10-LED standard 2-pin connection
- BUL10CMB** 10-LED weathertight connection
- BUL22CB** 27-LED standard 2-pin connection
- BUL52CB** 36-LED standard 2-pin connection

PACK QTY	10
FMVSS	(2) R
MATERIALS	Polycarbonate lens and housing
VOLT/AMP	BUL10: 12.8VDC - 0.260A
	BUL22: 12.8VDC - 0.125A
	BUL52: 12.8VDC - 0.275A
WT/DIMS	BUL10: .265 lb. / 6.50" x 2.375" x 1.688"
	BUL22/52: .397 lb. / 6.50" x 2.313" x 1.813"
WARRANTY	Lifetime LED Warranty



BUL10CB




BUL22CB



BUL52CB



BUL22CB/BUL52CB

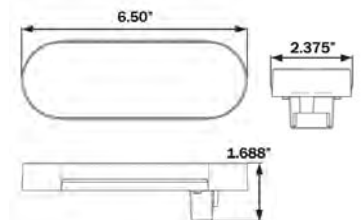

BUL10CB

HOLE CUT-OUT: 6.85" x 2.5" (1.25" R)