



America's Largest Offshore Vehicle Lighting Manufacturer.



ILL31/32/35 Series

LED Low Profile Dome Lights

- Low profile dome lights for semi-recess or surface mount
- Durable steel housing and replaceable polycarbonate lens
- Hard wired design includes power and ground wires
- Select from standard diode or SMD LED models



ILL31CB

Raw lumen output: 70 lm
Effective lumen output: 35 lm


- ILL31CB** Recess mount, 10 standard diodes
- ILL35CB** Recess mount, 10 SMD diodes
- ILL32CB** Surface mount, 10 SMD diodes
- ILL32CPG** Surface mount, 10 SMD diodes, .180 male bullets

MATERIALS Polycarbonate lens, plated steel housing

VOLT/AMP 12.8VDC - 0.024A

WT/DIMS ILL31/35: .243 lb / 5.75" x 2.75" x .938"
ILL32: .243 lb / 5.75" x 2.75" x .75"

WARRANTY Lifetime LED Warranty

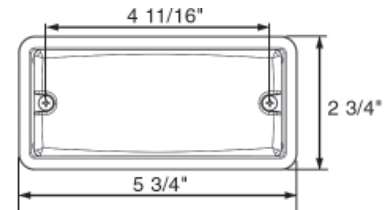

ILL31/32/35



ILL31/35 - recess mount



ILL32 - surface mount

