

GloLight™ 4" Sealed LED Stop/Turn/Tail Lights



LED LIFETIME WARRANTY
NO BULBS TO REPLACE EVER!

STL101 GROMMET MOUNT SERIES

- Sonically sealed, waterproof
- Mount in any 360 degree position
- Available in tinted and clear lens models
- Available with standard PL-3 or weathertight connection

BULK P/N	POLYPACK P/N	DESCRIPTION	QTY
RED STOP/TURN/TAIL LIGHT - 21 DIODES			
STL101RB	STL101RBP	PL-3 connection	10
STL101RMB	STL101RMBP	Weathertight connection	10
STL101RCB	STL101RCBP	Clear lens, red diodes, PL-3	10
STL101RCMB	STL101RCMBP	Clear lens, red diodes, weathertight	10
ACCESSORIES			
A45GB	A45GBP	Grommet	50
A45PB	A45PBP	Pigtail, 3-wire	100
A47PB	A47PBP	Right angle pigtail, 3-wire	100
A45PMB	A45PMBP	Weathertight pigtail	100
AL45PWTB	AL45PWTBP	Weathertight to PL-3 adaptor	50
FMVSS	Red S2 T2 I6		
MATERIALS	Polycarbonate lens and housing		
VOLT/AMP	12.8VDC - .375A Stop/Turn, .145A Tail		
WT/DIMS	.35 lbs. / 4.313" dia (PL-3: 2.188" D; Weathertight: 1.53" D)		
WARRANTY	Lifetime LED Warranty		

STOP/TURN


TAIL LIGHT



STL101RB



STL101RCB

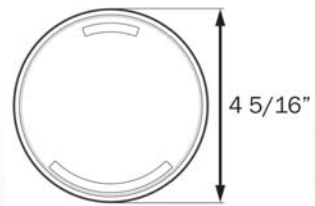

HOLE CUT-OUT: 4.5"

800-364-5483 / 918-683-9514
www.optronicsinc.com

