



America's Largest Offshore Vehicle Lighting Manufacturer.

STL23 Series


Miro-Flex™ 4" Round Sealed LED Lights

- Sonically sealed, waterproof
- Mount in any 360 degree position
- Accepts standard PL-3 plugs
- Available in 12V and 24V models

- STL23RB** 12-LED red 12V
- STL23CCRB** 12-LED clear lens, red reflector 12V
- STL23R24B** 12-LED red 24V
- STL23AB** 16-LED yellow 12V
- STL23A24B** 16-LED yellow 24V

FMVSS	Red S T I; Yellow I P
MATERIALS	Polycarbonate lens and housing
VOLT/AMP	Red: 12.8VDC - .208 Stop/Turn, .013A Tail 24.0VDC - .171 Stop/Turn, .061A Tail
	Yellow: 12.8VDC - .310 Turn, .046A Parking 24.0VDC - .171 Stop/Turn, .061 Parking
WT/DIMS	.265 lb / 4.313" x 4.313" x 1.938"
WARRANTY	Lifetime LED Warranty

LED LIFETIME WARRANTY
NO BULBS TO REPLACE EVER!

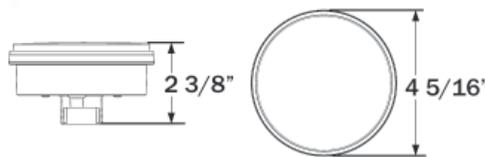

HOLE CUT-OUT: 4.5"

