



America's Largest Offshore Vehicle Lighting Manufacturer.



STL70 Series

High Diode Count 6" Oval Sealed LED Lights

- Sonically sealed, waterproof
- 48-56 LEDs for high diode count appearance
- Mount in any 360 degree position
- Accepts standard PL-3 plugs

STL70RB 48-LED red
STL70AB 48-LED yellow

FMVSS Red S T I P2; Yellow I P2 P
MATERIALS Polycarbonate lens and housing
VOLT/AMP Red: 12.8VDC - .362 Stop/Turn, .013A Tail
 Yellow: 12.8VDC - .400 Turn, .046A Parking
WT/DIMS .353 lb / 6.50" x 2.25" x 1.125"
WARRANTY Lifetime LED Warranty


LED LIFETIME WARRANTY
 NO BULBS TO REPLACE EVER!



STL70RB



STL70AB

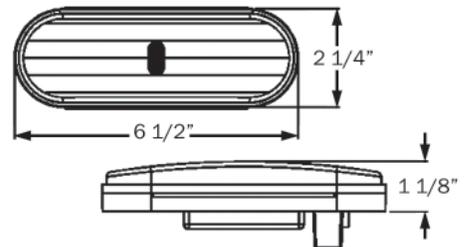

HOLE CUT-OUT: 6.85" X 2.5" (1.25" R)