**General Description:**

Task Lights are black with a slim profile design and mount recessed under metal storage units and shelves with spring steel clips and rails. Optional installation method utilizes key-hole slots to attach to supplied pan head screws to be mounted flush on other surfaces.

Electronic ballast for increased energy efficiency is a rapid-start HPF T5 with a Class A sound rating. Frequency rating is greater than 20 kHz.

T5 Triphosphor fluorescent bulb is installed, with a minimum rated lamp life of 10,000 hours. Bulb is TCLP compliant. Mercury content is less than 5 mg.

Plug in cord is a 9-foot round cord positioned at right end of unit with a 3 prong N.E. 90° plug. CH models include a re-settable circuit breaker on plug.

On/off switch is located on right rear corner on bottom of task light when mounted.

Four cord clips are included to accommodate routing of task light cord.

Diffuser lens opening is full width and 2.95" front to back, and is finished with pattern #12.

Interior reflector is a high-gloss white UV stable or reflective silver-color.

Models:


HH870924, HH870924CH for use on 24" Wide overheads
HH870930, HH870930CH for use on 30" and 36" overheads
HH870942, HH870942CH for use on 42" and 48" overheads
HH870960, HH870960CH for use on 60" Wide overheads

Shipping Information:

Task Lights ship assembled in a full corrugated carton with innerpack for protection.

Compliance:

Product is UL Listed and UL Certified to Canadian Standards (or CSA Certified).

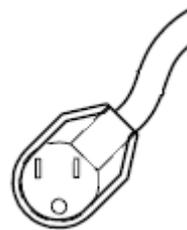

Plug Detail – View from back side of plug

The HON Company
200 Oak Street
Muscatine, IA 52761
800-833-3964
hon.com