



PROTECTIVE INDUSTRIAL PRODUCTS

Zenon Z12R Specification Sheet

SAFETY EYEWEAR READERS

PRODUCT DESCRIPTION:

Zenon Z12R bi-focal safety eyewear, rimless front, frame with rubber tip ends.

- 28mm wide reading magnifier provides wearer with enough lens to view work;
- Molded bridge design fits most wearers;
- Thin, flexible temples provide secure fit without pinching;
- Rimless design for light weight;
- Meets ANSI Z87+ standard.

Applications:

Used for general manufacturing and anywhere eye protection is needed.

TECHNICAL DATA:

Base Curve: 9.25

Packaging: 12 units per dozen, 144 units per case

Case Dimensions (cm): 64 x 29.5 x 32.5 / (in): 25.2 x 11.6 x 12.8

Case Weight: 15.4 lbs / 7.0 kg

Manufacturer Certifications: ISO 9001:2000 certified

Country of Origin/Harmonization Code: Taiwan/9004.90.0000




Polycarbonate lenses block 99.9% of the sun's ultraviolet rays. This ultraviolet protection has already been incorporated within the lens material when the lenses are being produced.

Item #	Lens Material	Lens Color	Lens Coating	Frame Design	Frame Color	UPC # Box	UPC # Case
250-27-0010	Polycarbonate	Clear	Bifocal +1.00, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314062444	02616314062443
250-27-0012	Polycarbonate	Clear	Bifocal +1.25, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314062451	02616314062450
250-27-0015	Polycarbonate	Clear	Bifocal +1.50, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314045110	02616314045110
250-27-0017	Polycarbonate	Clear	Bifocal +1.75, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314062468	02616314062467
250-27-0020	Polycarbonate	Clear	Bifocal +2.00, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314045127	02616314045127
250-27-0022	Polycarbonate	Clear	Bifocal +2.25, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314062475	02616314062474
250-27-0025	Polycarbonate	Clear	Bifocal +2.50, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314045134	02616314045134
250-27-0027	Polycarbonate	Clear	Bifocal +2.75, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314062482	02616314062481
250-27-0030	Polycarbonate	Clear	Bifocal +3.00, Hard Coat	Rimless front, rubber tip end	Clear temples	01616314045141	02616314045141
250-27-0115	Polycarbonate	Gray	Bifocal +1.50, Hard Coat	Rimless front, rubber tip end	Gray temples	01616314045158	02616314045158
250-27-0120	Polycarbonate	Gray	Bifocal +2.00, Hard Coat	Rimless front, rubber tip end	Gray temples	01616314045165	02616314045165
250-27-0125	Polycarbonate	Gray	Bifocal +2.50, Hard Coat	Rimless front, rubber tip end	Gray temples	01616314045172	02616314045172
250-27-0130	Polycarbonate	Gray	Bifocal +3.00, Hard Coat	Rimless front, rubber tip end	Gray temples	01616314045189	02616314045189

DIMENSIONS:

Size Available	One size
Over Length (mm) – A	155
(in)	6.1
Lens Height (mm) – B	40
(in)	1.6
Over Width (mm) – C	143
(in)	5.6

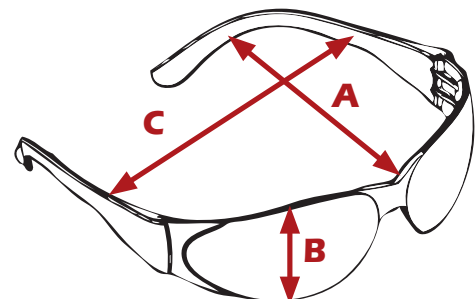

This document is the property of PIP and the information contained herein is proprietary to PIP.

Protective Industrial Products | 26 Computer Drive East | Albany, NY 12205

Phone: 518-861-0133 | Toll free: 800-262-5755 | Fax: 518-861-0144 | www.pipusa.com | sales@pipusa.com