



BR LED with AirFlux Technology

9.5BR30/SLIM/2700 DIM 120V

Philips BR Dimmable LED Lamps with AirFlux technology provide a soft, diffused level of light and smooth dimming to reduce glare. The sleek, lightweight design is ideal for downlighting.

Product data

• General Characteristics

Cap-Base	E26
Bulb	BR30
Rated Avg. Life (Hours)	25000 hr

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Beam Angle	110 D
Correlated Color Temperature	2700 K
CRI	80
Luminous Efficacy Lamp	68.42 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	650 Lm

• Electrical Characteristics

Wattage	9.5 W
Wattage Technical	9.5 W
Voltage	120 V
Line Frequency	60 Hz
Power Factor	0.85 -

Lamp Current mA	95 mA
Dimmable	Yes
Wattage Equivalent	65 W
Starting Time	0.5 (max) s

• Measuring Conditions

Switching cycle	15000X
-----------------	--------

• Product Dimensions

Overall Length C	128 mm
Diameter D	95 mm


• Product Data

Product number	452367
Full product name	9.5BR30/SLIM/2700 DIM 120V
Short product name	9.5BR30/SLIM/2700 DIM 120V
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677452360
Bar code on case	50046677452365
Logistics code(s)	929001111804
eop_net_weight_pp	0.064 kg



PHILIPS

Dimensional drawing

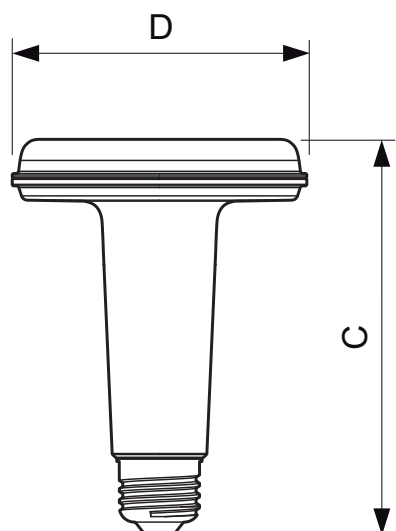

9.5BR30/SLIM/2700 DIM 120V



E26



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, July 15
data subject to change