



A-Shape LED

20A21/2700 3WAY 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

• General Characteristics

Cap-Base	E26
Bulb	A21
Rated Avg. Life (Hours)	25000 hr
Nominal Lifetime hours	25000 hr

Warm-up Time to 60% Light Outp	instant full light
Suitable for accent lighting	No

• Light Technical Characteristics

Color Code	827
Color Designation	Warm White
Correlated Color Temperature	2700 K
Approximate Lumens	1620 Lm
CRI	80
Luminous Efficacy Lamp	81 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	1620 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	<6

• Temperature Characteristics

T-case maximum	88 C
----------------	------

• Environmental characteristics

Energy consumption kWh/1000h	20 kWh
------------------------------	--------

• Measuring Conditions

Switching cycle	50000X
-----------------	--------

• Product Dimensions

Overall Length C	125 mm
Diameter D	66 mm

• Electrical Characteristics

Wattage	20 W
Voltage	120 V
Line Frequency	60 Hz
Power Factor	0.7 -
Lamp Current mA	175 mA
Dimmable	Yes
Wattage Equivalent	100 W
Rated Wattage	20 W
Starting Time	0.5 (max) s


• Product Data

Product number	453365
Full product name	20A21/2700 3WAY 6/1
Short product name	20A21/2700 3WAY 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677453367
Bar code on case	50046677453362
Logistics code(s)	929001121904
eop_net_weight_pp	0.245 kg



PHILIPS

Dimensional drawing

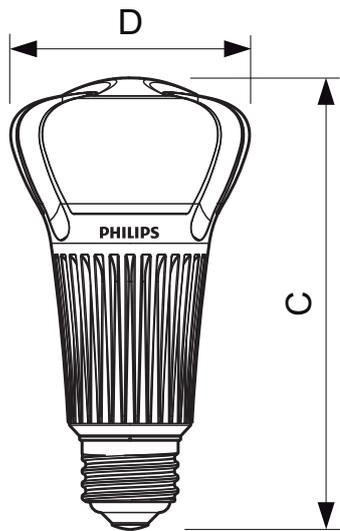

E26

20A21/2700 3WAY 6/1

Product	C (Norm)	D (Norm)
LED 20-100W E26/827 120V A21	125	66



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, November 24
data subject to change