



# MR16 LED

10MR16/F24 4000 DIM HO 10/1

Philips MR16 Dimmable LED Lamps provide ambient level light to illuminate hard to maintain applications. Increased transformer compatibility allows for operation on a wider range of transformers. Available in dimmable and non-dimmable versions, these lamps are ideal for track and open recessed fixtures in retail, hospitality and residential spaces.

## Product data

### • General Characteristics

Cap-Base	GU5.3
Bulb	MR16 [MR 16inch/50mm]
Rated Avg. Life (Hours)	30000 hr
Nominal Lifetime hours	30000 hr

### • Light Technical Characteristics

Color Code	840
Color Designation	Cool White
Beam Angle	24 D
Beam Description	24D [Medium beam]
Correlated Color Temperature	4000 K
Approximate Lumens	660 Lm
Approx. MBCP	3010 cd
CRI	80
Luminous Efficacy Lamp	66.00 Lm/W
Color Temp. (Kelvin)	4000 K [CCT 4000K]
Rated Luminous Flux	660 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	6 steps
Rated Beam Angle	24 D

### • Electrical Characteristics

Wattage	10 W
Wattage Technical	10 W
Voltage	12 V
Line Frequency	50-60 Hz
Power Factor	0.8 -
Lamp Current mA	1200 mA
Dimmable	Yes

Wattage Equivalent	50 W
Rated Wattage	10 W
Starting Time	0.5 (max) s
Warm-up Time to 60% Light Outp	instant full light
Suitable for accent lighting	Yes

### • Temperature Characteristics

T-case maximum	90 C
----------------	------

### • Environmental characteristics

Energy Efficiency Label (EEL)	A
-------------------------------	---

### • Measuring Conditions

Switching cycle	50000X
-----------------	--------

### • Product Dimensions

Overall Length C	50.3 mm
Diameter D	54.5 mm

### • Product Data

Product number	432419
Full product name	10MR16/F24 4000 DIM HO 10/1
Short product name	10MR16/F24 4000 DIM HO 10/1
Pieces per Sku	1
eop_pck_cfg	10
Skus/Case	10
Bar code on pack	46677432416
Bar code on case	50046677432411
Logistics code(s)	929000260204




# PHILIPS

# MR16 LED


eop\_net\_weight\_pp 0.045 kg

## Dimensional drawing

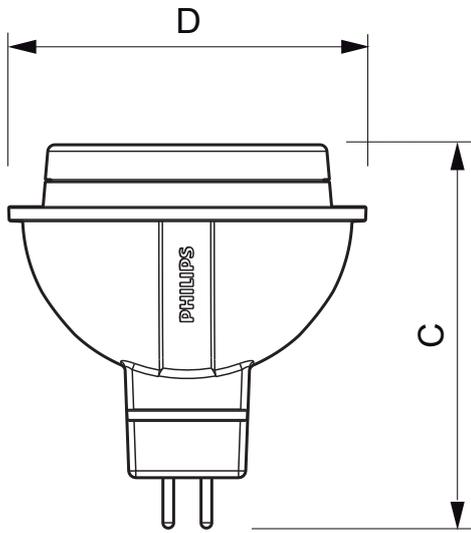

### 10MR16/F24 4000 DIM HO 10/1

Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED D 10-50W 840 MR16 24D	50.3	-	54.5	-

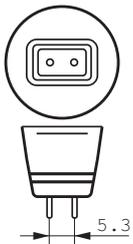

GU5.3



© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, April 8  
data subject to change