



# MR16 LED

7MR16/S15 4000 DIM AF 10/1

Philips MR16 Dimmable LED Lamps provide ambient level light to illuminate hard to maintain applications. Increased transformer compatibility allows for operation on a wider range of transformers. Available in dimmable and non-dimmable versions, these lamps are ideal for track and open recessed fixtures in retail, hospitality and residential spaces.

## Product data

### • General Characteristics

Cap-Base	GU5.3
Bulb	MR16 [MR 16inch/50mm]
Rated Avg. Life (Hours)	40000 hr
Nominal Lifetime hours	40000 hr

### • Light Technical Characteristics

Color Code	840
Color Designation	Cool White
Beam Angle	15 D
Beam Description	- [-]
Correlated Color Temperature	4000 K
Approximate Lumens	440 Lm
Approx. MBCP	3250 cd
CRI	80
Luminous Efficacy Lamp	62.86 Lm/W
Color Temp. (Kelvin)	4000 K [CCT 4000K]
Rated Luminous Flux	440 Lm
LLMF - end nominal lifetime	40000 %
Colour consistency	6 steps
Rated Beam Angle	15 D
Luminous flux in 90° cone	420 Lm

### • Electrical Characteristics

Wattage	7 W
Wattage Technical	7 W
Voltage	12 V
Line Frequency	50-60 Hz
Power Factor	0.7 -

Lamp Current mA	715 mA
Dimmable	Yes
Wattage Equivalent	35 W
Rated Wattage	7.0 W
Starting Time	0.5 s
Warm-up Time to 60% Light Outp	instant full light
Suitable for accent lighting	Yes

### • Temperature Characteristics

T-case maximum	110 C
----------------	-------

### • Environmental characteristics

Energy Efficiency Label (EEL)	A
-------------------------------	---

### • Measuring Conditions

Switching cycle	50000X
-----------------	--------

### • Product Dimensions

Overall Length C	50 mm
Diameter D	54 mm

### • Product Data

Product number	432674
Full product name	7MR16/S15 4000 DIM AF 10/1
Short product name	7MR16/S15 4000 DIM AF 10/1
Pieces per Sku	1
Skus/Case	10
Bar code on pack	46677432676
Bar code on case	50046677432671




# PHILIPS

# MR16 LED

Logistics code(s) 929000262904


eop\_net\_weight\_pp 0.060 kg

## Dimensional drawing

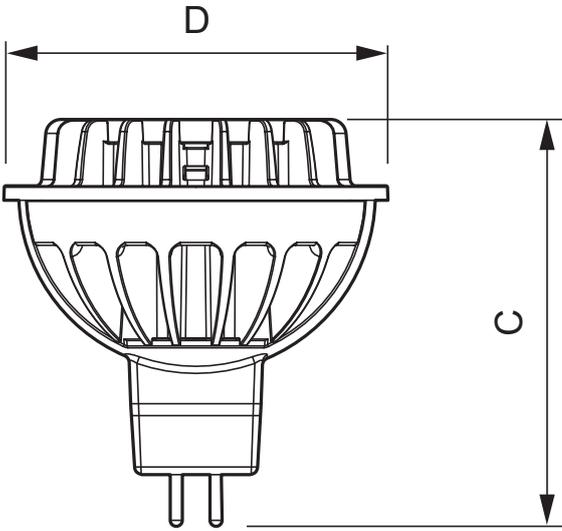


### 7MR16/S15 4000 DIM AF 10/1

Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED D 7-35W 4000K MR16 15D	50	-	54	-

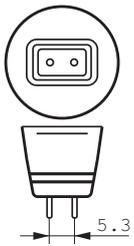

GU5.3

## Photometric data

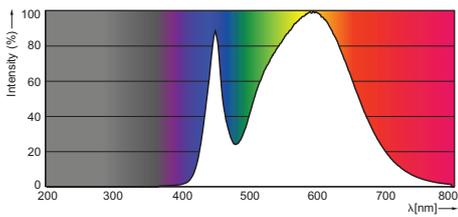

7-35W, 7-50W MR16 4000K



© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, April 8  
data subject to change