

# CorePro LED Lamps

13PAR38/COREPRO/F25 2700 AF 6/1

Philips CorePro LED Lamps provide an energy efficient lighting solution



## Product data

### • General Characteristics

|                         |                  |
|-------------------------|------------------|
| Cap-Base                | E26              |
| Bulb                    | PAR38 [PAR38 mm] |
| Rated Avg. Life (Hours) | 25000 hr         |

### • Light Technical Characteristics

|                              |                    |
|------------------------------|--------------------|
| Color Code                   | WW                 |
| Color Designation            | Warm White         |
| Beam Angle                   | 25 D               |
| Beam Description             | 25D [Medium beam]  |
| Correlated Color Temperature | 2700 K             |
| Approximate Lumens           | 750 Lm             |
| Approx. MBCP                 | 3200 cd            |
| CRI                          | 84                 |
| Luminous Efficacy Lamp       | 57.69 Lm/W         |
| Color Temp. (Kelvin)         | 2700 K [CCT 2700K] |
| Rated Luminous Flux          | 750 Lm             |

### • Electrical Characteristics

|                   |       |
|-------------------|-------|
| Wattage           | 13 W  |
| Wattage Technical | 13 W  |
| Voltage           | 120 V |
| Line Frequency    | 60 Hz |
| Power Factor      | 0.7 - |

|                    |        |
|--------------------|--------|
| Lamp Current mA    | 119 mA |
| Dimmable           | No     |
| Wattage Equivalent | 75 W   |
| Starting Time      | 0.5 s  |

### • Measuring Conditions

|                 |        |
|-----------------|--------|
| Switching cycle | 20000X |
|-----------------|--------|

### • Product Dimensions

|                  |        |
|------------------|--------|
| Overall Length C | 130 mm |
| Diameter D       | 120 mm |

### • Product Data

|                    |                                 |
|--------------------|---------------------------------|
| Product number     | 426320                          |
| Full product name  | 13PAR38/COREPRO/F25 2700 AF 6/1 |
| Short product name | 13PAR38/COREPRO/F25 2700 AF 6/1 |
| Pieces per Sku     | 1                               |
| eop_pck_cfg        | 6                               |
| Skus/Case          | 6                               |
| Bar code on pack   | 46677426323                     |
| Bar code on case   | 50046677426328                  |
| Logistics code(s)  | 929000231804                    |
| eop_net_weight_pp  | 0.370 kg                        |

## Warnings and Safety


- Suitable for use in damp locations.

- Not for use in totally enclosed luminaires.
- Before replacing, turn off power and let lamp cool to avoid electrical shock or burn.



# PHILIPS

## Dimensional drawing

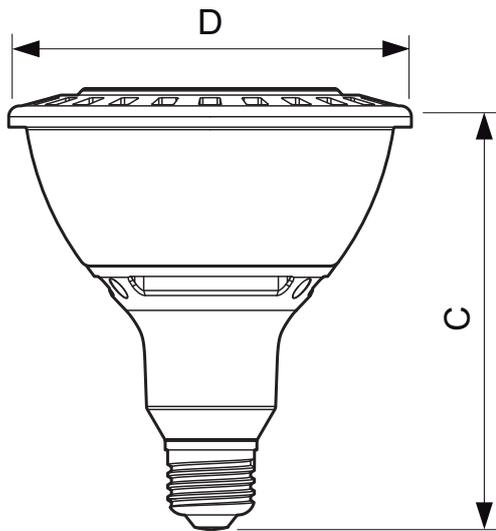

E26

### 13PAR38/COREPRO/F25 2700 AF 6/1

| Product                     | C (Norm) | C1 (Max) | D (Norm) | D1 (Norm) |
|-----------------------------|----------|----------|----------|-----------|
| LED 13W E26 2700K PAR38 25D | 130      | -        | 120      | -         |



© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, April 8  
data subject to change