

CorePro LED Lamps

13PAR38/COREPRO/F25 3000 AF 6/1

Philips CorePro LED Lamps provide an energy efficient lighting solution



Product data

• General Characteristics

Cap-Base	E26
Bulb	PAR38 [PAR38 mm]
Rated Avg. Life (Hours)	25000 hr

• Light Technical Characteristics

Color Code	WH
Color Designation	White
Beam Angle	25 D
Beam Description	25D [Medium beam]
Correlated Color Temperature	3000 K
Approximate Lumens	830 Lm
Approx. MBCP	3200 cd
CRI	84
Luminous Efficacy Lamp	63.85 Lm/W
Color Temp. (Kelvin)	3000 K [CCT 3000K]
Rated Luminous Flux	830 Lm

• Electrical Characteristics

Wattage	13 W
Wattage Technical	13 W
Voltage	120 V
Line Frequency	60 Hz

Power Factor	0.7 -
Lamp Current mA	119 mA
Dimmable	No
Wattage Equivalent	75 W
Starting Time	0.5 s

• Measuring Conditions

Switching cycle	20000X
-----------------	--------

• Product Dimensions

Overall Length C	130 mm
Diameter D	120 mm

• Product Data

Product number	426338
Full product name	13PAR38/COREPRO/F25 3000 AF 6/1
Short product name	13PAR38/COREPRO/F25 3000 AF 6/1
Pieces per Sku	1
Skus/Case	6
Bar code on pack	46677426330
Bar code on case	50046677426335
Logistics code(s)	929000231904
eop_net_weight_pp	0.370 kg

Warnings and Safety


- Suitable for use in damp locations.

- Not for use in totally enclosed luminaires.
- Before replacing, turn off power and let lamp cool to avoid electrical shock or burn.



PHILIPS

Dimensional drawing

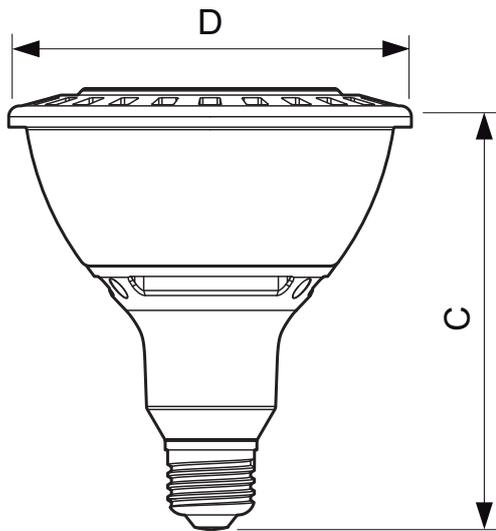

E26

13PAR38/COREPRO/F25 3000 AF 6/1

Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED 13W E26 3000K PAR38 25D	130	-	120	-



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 8
data subject to change