



BR30 DimTone LED

13BR30/END/F90 22K-27K 6/1

Philips BR30 DimTone Dimmable LED Lamps with AirFlux Technology provide a soft, diffused level of light and smooth dimming from 2700K to 2200K to create a warm inviting atmosphere.

Product data

• General Characteristics

Cap-Base	E26
Bulb	BR30
Bulb Finish	White
Rated Avg. Life (Hours)	25000 hr

• Light Technical Characteristics

Color Code	WW
Beam Angle	90 D
Beam Description	90D [Flood]
Correlated Color Temperature	2700 K
CRI	83
Luminous Efficacy Lamp	56.15 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	730 Lm

• Electrical Characteristics

Wattage	13 W
Wattage Technical	13 W
Voltage	120 V
Line Frequency	60 Hz
Power Factor	0.9 -
Lamp Current mA	128 mA

Dimmable	Yes
Wattage Equivalent	65 W
Starting Time	0.5 s

• Measuring Conditions

Switching cycle	20000X
-----------------	--------

• Product Dimensions

Overall Length C	131.5 mm
Overall Length C [inch]	5.177 (max) in
Diameter D	95 mm

• Product Data

Product number	426445
Full product name	13BR30/END/F90 22K-27K 6/1
Short product name	13BR30/END/F90 22K-27K 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677426446
Bar code on case	50046677426441
Logistics code(s)	929000234404
eop_net_weight_pp	0.275 kg

Warnings and Safety


- Suitable for use in damp locations.

- Do not use in outdoor fixtures.
- Not for use in totally enclosed luminaires.
- Before replacing, turn off power and let lamp cool to avoid electrical shock or burn.



PHILIPS

Dimensional drawing

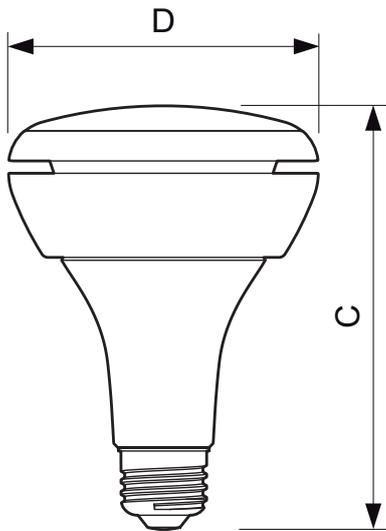

E26

13BR30/END/F90 22K-27K 6/1



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 8
data subject to change