



Candle LED

4.5F15/END/2700-E26 DIM 8/1

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

Product data

• General Characteristics

Cap-Base	E26
Bulb	F15
Rated Avg. Life (Hours)	25000 hr
Nominal Lifetime hours	25000 hr

Line Frequency	60 Hz
Power Factor	0.6 -
Lamp Current mA	55 mA
Dimmable	Yes
Wattage Equivalent	40 W
Rated Wattage	4.5 W
Starting Time	0.5 s

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Correlated Color Temperature	2700 K
Approximate Lumens	320 Lm
CRI	80
Luminous Efficacy Lamp	71.11 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	320 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	6 steps

• Measuring Conditions

Switching cycle	50000X
-----------------	--------

• Product Dimensions

Overall Length C	112 mm
Diameter D	47 mm

• Product Data

Product number	429357
Full product name	4.5F15/END/2700-E26 DIM 8/1
Short product name	4.5F15/END/2700-E26 DIM 8/1
Pieces per Sku	1
eop_pck_cfg	8
Skus/Case	8
Bar code on pack	46677429355
Bar code on case	50046677429350
Logistics code(s)	929000243904
eop_net_weight_pp	0.055 kg


• Electrical Characteristics

Wattage	4.5 W
Wattage Technical	4.5 W
Voltage	120 V



PHILIPS

Dimensional drawing

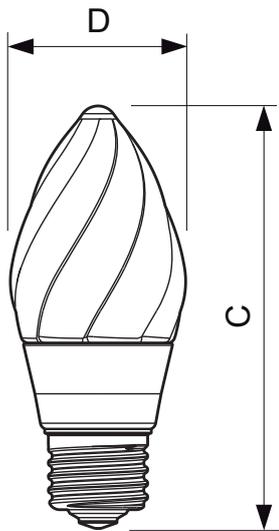

E26

4.5F15/END/2700-E26 DIM 8/1

Product	C (Norm)	D (Norm)
LED 4.5W E26 2700K 120V F15	112	47



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, April 8
data subject to change