

PORTER CABLE®

20V MAX* LITHIUM ION 1/2 IN. DRILL/DRIVER KIT

PCCK600LB



PERFORMANCE

330 UNIT WATTS OUT
0-400, 0-1,600 RPMS

ERGONOMICS

7-3/4 IN. LENGTH
3.5 LBS.

EASE OF USE

METAL RATCHETING CHUCK
BATTERY FUEL GAUGE
LED WORK LIGHT




INCLUDES



LITHIUM

PORTER CABLE®

20V MAX* LITHIUM ION 1/2 IN. DRILL/DRIVER KIT

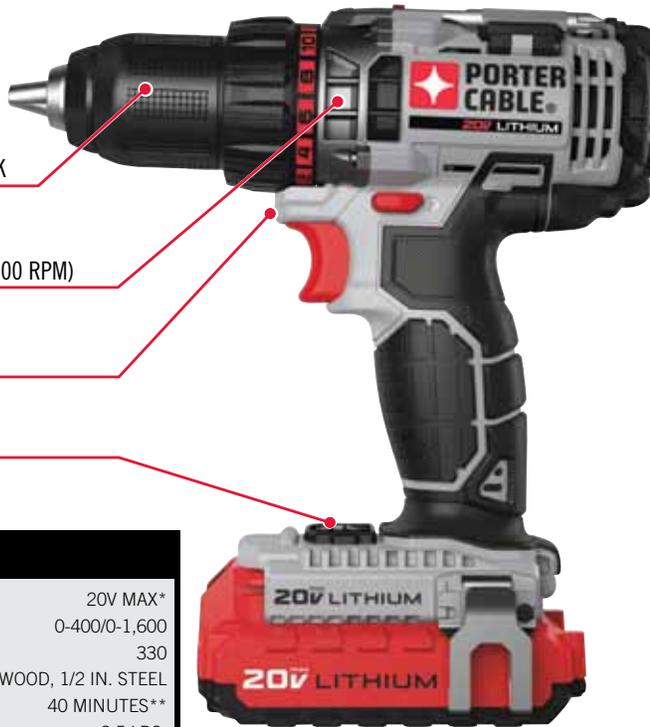

1/2 IN. RATCHETING METAL CHUCK

2-SPEED GEARBOX (0-400 / 0-1,600 RPM)

INTEGRAL LED WORKLIGHT

BATTERY FUEL GAUGE

SPECIFICATIONS:

VOLTS	20V MAX*
RPM	0-400/0-1,600
MAX WATTS OUT	330
CAPACITY	1 IN. WOOD, 1/2 IN. STEEL
CHARGE TIME	40 MINUTES**
WEIGHT WITH BATTERY	3.5 LBS.
BATTERY TYPE	LITHIUM ION

**80% CAPACITY FOR PORTER-CABLE BATTERIES



ALSO AVAILABLE IN PORTER-CABLE 20V MAX*

PCCK640LB
LITHIUM ION 1/4 IN.
HEX IMPACT DRIVER



3	3 YEAR LIMITED WARRANTY
1	1 YEAR FREE SERVICE
90	90 DAY MONEY BACK GUARANTEE

*Maximum initial battery pack voltage (measured without a workload) is 20 volts. Nominal voltage is 18.

The following are PORTER-CABLE trademarks for one or more power tools and accessories: a gray and black color scheme and a "four point star" design. Contents may vary. Does not affect function. PORTER-CABLE will repair or replace, without charge, any defects due to faulty materials or workmanship in tools for three years from date of purchase (two years for batteries). If you have any problems with this product or questions under this warranty, contact us at 1-888-848-5175.

#ICPCK600LBSS IC Porter Cable PCK600LB Sell Sheet © 2012

LITHIUM