


# Punched Walk Ramps

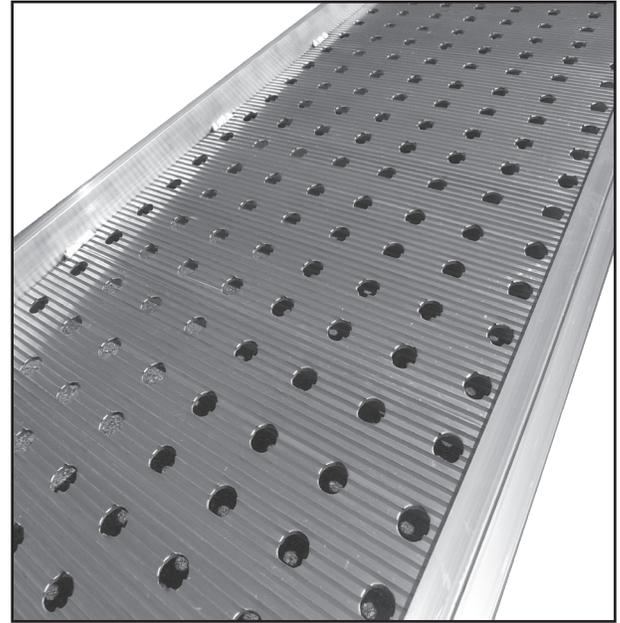

- Holes are punched in the material, providing superior traction
- Won't collect ice, mud, snow, or debris
- Punched design reduces the weight without sacrificing strength
- Custom widths available
- Apron End or Steel hooks to lock onto truck bed for flush-type direct entry

SPECIFICATIONS										
Type	Height Range (in.)		Length (ft.)	Cap. (lbs)	26" Width		28" Width		38" Width	
	Min	Max			Model #	Wt. (lbs)	Model #	Wt. (lbs)	Model #	Wt. (lbs)
A Apron End	6	21	6	2000	PRP-2606-A	43	PRP-2806-A	44	PRP-3806-A	57
	6	25	7	1800	PRP-2607-A	50	PRP-2807-A	52	PRP-3807-A	66
	6	29	8	1700	PRP-2608-A	56	PRP-2808-A	59	PRP-3808-A	74
	6	33	9	1650	PRP-2609-A	63	PRP-2809-A	66	PRP-3809-A	82
	6	38	10	1500	PRP-2610-A	69	PRP-2810-A	73	PRP-3810-A	91
	6	46	12	1400	PRP-2612-A	83	PRP-2812-A	87	PRP-3812-A	107
	6	54	14	1200	PRP-2614-A	96	PRP-2814-A	100	PRP-3814-A	124
	6	62	16	1000	PRP-2616-A	110	PRP-2816-A	114	PRP-3816-A	141
F Hook End	6	23	6	2000	PRP-2606-F	44	PRP-2806-F	45	PRP-3806-F	58
	6	27	7	1800	PRP-2607-F	51	PRP-2807-F	53	PRP-3807-F	67
	6	31	8	1700	PRP-2608-F	57	PRP-2808-F	60	PRP-3808-F	75
	6	35	9	1650	PRP-2609-F	64	PRP-2809-F	67	PRP-3809-F	83
	6	40	10	1500	PRP-2610-F	70	PRP-2810-F	74	PRP-3810-F	92
	6	48	12	1400	PRP-2612-F	84	PRP-2812-F	88	PRP-3812-F	108
	6	56	14	1200	PRP-2614-F	97	PRP-2814-F	101	PRP-3814-F	125
	6	64	16	1000	PRP-2616-F	111	PRP-2816-F	115	PRP-3816-F	142