


## Hand Crank / Spring Retractable Cable Welding Reels Series CEA / WC



CEA30006

- Designed to improve safety in the work area with an increase in efficiency and productivity
- Cable reels have a current path through a continuous 400 AMP, 90 V DC (maximum) rated enclosed slip ring

- Welding cable reels store work lead or electrode lead, up to #2/0, safely and effectively when not in use. Each lead requires a separate reel. When welding also refer to ANSI/Asc Z 49.1
- Stores cable when not in use, eliminating tangled, kinked welding cables
- Maintains proper bend radius of cables, providing longer cable life
- Keeps work area and vehicles better organized, resulting in better space utilization

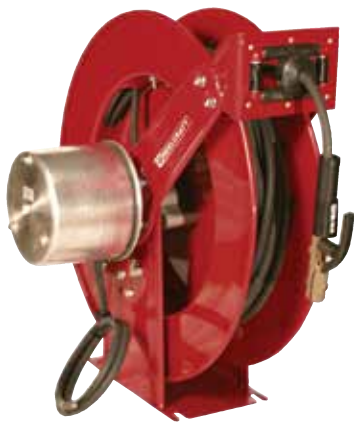

WC80001



Shown with electrode, clamp and cable (not included)

WC7000



### Features - Hand Crank Reels

- ✓ All-bolted heavy gauge steel construction provides long life and ease of use and maintenance.
- ✓ Manual drum lock prevents spool from turning when not in use preventing unwanted pay out of cable.

Dimensions - Size Index	1		2	
	in	mm	in	mm
	A	20 <sup>1</sup> / <sub>4</sub>	514	25 <sup>3</sup> / <sub>8</sub>
B	19 <sup>3</sup> / <sub>4</sub>	502	24	610
C	7 <sup>7</sup> / <sub>8</sub>	200	10	254
D	3 <sup>7</sup> / <sub>8</sub>	98	6	152
E	13 <sup>1</sup> / <sub>4</sub>	337	15 <sup>5</sup> / <sub>8</sub>	397

Dimensions - Size Index	3		4	
	in	mm	in	mm
	A	6	152	12
B	9 <sup>3</sup> / <sub>4</sub>	248	15 <sup>3</sup> / <sub>4</sub>	400
C	11	279	17	432
D	15	381	21	533
E	21	533	27	686

Four 1/2" (12.7 mm) diameter mounting holes.

### Caution:

If cable reels are to be used for extended periods of time, unwind all cable from reel to prevent heat build-up. For indoor non weather-tight applications only.

### Available Options

#### Roller Guides

See page 47



#### Replacement Bumpers

See page 49



Model without cable & bumper	Cable Size				Shipping Weight		Size Index #				
	#2 (31mm <sup>2</sup> )		#1 (39mm <sup>2</sup> )		#1/0 (50mm <sup>2</sup> )			#2/0 (62mm <sup>2</sup> )			
	ft	m	ft	m	ft	m		lbs	kg		
CEA30006	300	91	250	76	200	61	150	46	46	21	3
CEA30012	500*	152	500*	152	400	122	300	91	54	24	4
WC7000	-----	-----	50	15	50	15	50	15	58	26	1
WC80001	-----	-----	75	23	75	23	75	23	102	46	2
WC80002	-----	-----	100	30	-----	-----	-----	-----	104	47	2

\*May exceed maximum cable length allowable for most welding applications. **NOTE:** Each cable requires separate reel. Reference page 4 for guide arm positions.

Models listed with an icon can ship same day upon request when the order is received by 11:30 AM Eastern Time for quantities of 5 or fewer.

Indiana Warehouse

Indiana & California Warehouses

California Warehouse

Canadian Warehouse