

PK polycarbonate screw cover junction box



PK accessories Page 32 System accessories Page 531 Polyamide cable gland Page 715

Material:

- Housing of fiberglass reinforced polyamide
- Cover either transparent (version .100) or grey (version .000), made from fiberglass-reinforced polycarbonate
- Cover screws from polyamide
- Insulating bung from polyethylene
- All-round foamed-in PU seal

Color:

RAL 7035

Protection rating:


UL/cUL Type 4X
(IP 66 to EN 60 529/10.91)
UL File #: E86711

Configuration:

- Enclosure with cover
- Cover screws
- Insulating bungs for wall mounting screws

Detailed drawings:

Available at www.rittal.us

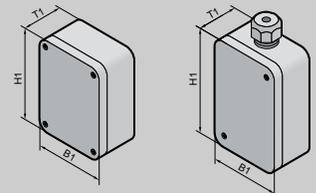

Depth: 1.4 - 3.2" (35 - 81 mm), Height: 2.0 - 3.7" (52 - 94 mm)

Height (H1) inches (mm)	2.0 (52)	2.6 (65)	2.6 (65)	2.6 (65)	2.6 (65)	2.6 (65)	3.7 (94)	3.7 (94)	Page
Width (B1) inches (mm)	2.0 (50)	2.0 (50)	2.6 (65)	2.6 (65)	3.7 (94)	3.7 (94)	3.7 (94)	3.7 (94)	
Depth (T1) inches (mm)	1.4 (35)	1.4 (35)	2.2 (57)	3.2 (81)	2.2 (57)	3.2 (81)	2.2 (57)	3.2 (81)	
Part No. with cable gland	9530.000	9531.000	–	–	–	–	–	–	
Part No. with solid cover	–	–	9500.000	9501.000	9502.000	9503.000	9504.000	9505.000	
PU	10	10	12	12	8	8	6	6	

Accessories

Mounting panel	–	9541.000	9542.000	–
PU	10	12		
Support rail (PU 12)				
TS 35/7.5	Installation in the height	–	9564.000	32
	Installation in the width	–	9564.000	32

Depth: 2.2 - 3.9" (57 - 99 mm), Height: 3.7 - 5.1" (94 - 130 mm)

Height (H1) inches (mm)	3.7 (94)	3.7 (94)	3.7 (94)	3.7 (94)	4.3 (110)	4.3 (110)	5.1 (130)	5.1 (130)	Page
Width (B1) inches (mm)	5.1 (130)	5.1 (130)	7.1 (180)	7.1 (180)	4.3 (110)	4.3 (110)	5.1 (130)	5.1 (130)	
Depth (T1) inches (mm)	2.2 (57)	3.2 (81)	2.2 (57)	3.2 (81)	2.6 (66)	3.5 (90)	3.0 (75)	3.9 (99)	
Part No. with solid cover	9508.000	9509.000	9512.000	9513.000	9506.000	9507.000	9510.000	9511.000	
Part No. with transparent cover	9508.100	9509.100	9512.100	9513.100	–	–	9510.100	9511.100	
PU	4	4	2	2	6	6	4	4	

Accessories

Mounting panel	9544.000	9546.000	9543.000	9545.000	32
PU	12	10	12	10	
Support rail (PU 12)					
TS 35/7.5	Installation in the height	9564.000	9565.000	32	
	Installation in the width	9565.000	9566.000	9564.000	9565.000

PK polycarbonate screw cover junction box

Depth: 3.5 - 6.5" (90 - 165 mm), Height: 4.3 - 7.1" (110 - 180 mm)

Height (H1) inches (mm)	4.3 (110)	4.3 (110)	4.3 (110)	7.1 (180)	7.1 (180)	7.1 (180)	Page
Width (B1) inches (mm)	7.1 (180)	7.1 (180)	7.1 (180)	7.2 (182)	7.2 (182)	7.2 (182)	
Depth (T1) inches (mm)	3.5 (90)	4.4 (111)	6.5 (165)	3.5 (90)	4.4 (111)	6.5 (165)	
Part No. with solid cover	9514.000	9515.000	9516.000	9517.000	9518.000	9519.000	
Part No. with transparent cover	9514.100	9515.100	9516.100	9517.100	9518.100	9519.100	
PU	2	2	2	1	1	1	

Accessories							
Mounting panel	9547.000			9548.000			32
PU	10			10			
Support rail TS 35/7.5 (PU 12)	Installation in the height	9564.000		9566.000			32
	Installation in the width	9566.000		9566.000			32

Depth: 3.5 - 6.5" (90 - 165 mm), Height: 7.1 - 10.0" (180 - 254 mm)

Height (H1) inches (mm)	7.1 (180)	7.1 (180)	7.1 (180)	10.0 (254)	10.0 (254)	Page
Width (B1) inches (mm)	10.0 (254)	10.0 (254)	10.0 (254)	14.2 (360)	14.2 (360)	
Depth (T1) inches (mm)	3.5 (90)	4.4 (111)	6.5 (165)	4.4 (111)	6.5 (165)	
Part No. with solid cover	9520.000	9521.000	9522.000	9523.000	9524.000	
Part No. with transparent cover	9520.100	9521.100	9522.100	9523.100	9524.100	
PU	1	1	1	1	1	

Accessories							
Mounting panel	9549.000			9550.000			32
PU	8			4			
Support rail TS 35/7.5 (PU 12)	Installation in the height	9566.000		9567.000			32
	Installation in the width	9567.000		9568.000			32