

Doors/locks

Viewing panels/operating panels



Viewing window stainless steel

Fitted as standard with internal 130° hinges and all-round seal. The double-bit lock insert may be exchanged for 27 mm lock inserts, type A, and Ergoform-S handle 2452.000.

Material:

Stainless steel Type 304,
Single-pane safety glass

Protection rating:

IP 54 to IEC 60 529

 

Configuration:

Assembly parts

Accessories:

- Lock inserts, 27 mm, version A, see page 607
- Ergoform-S handle 2452.000, see page 605

Height inches (mm)	Width inches (mm)	Depth inches (mm)	Part No.
24 (600)	21 (522)	2 (38)	2793.560

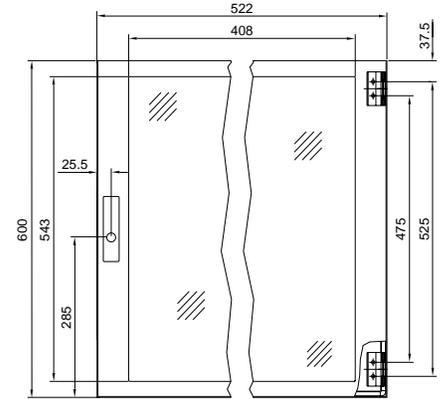

Window kits

Rittal window kits can be installed in most Rittal enclosures of suitable size. Window kits include all necessary hardware. Oil-resistant gaskets ensure a tight seal around the entire window.

Material/surface finish:

Carbon Steel: 14 ga, painted
RAL 7035 (light grey)
Stainless Steel 304: 14 ga
Stainless Steel 316L: 14 ga

Protection rating:

Carbon steel complies with NEMA 4
Stainless steel complies with NEMA 4X

Note:

Allow for clearance of gaskets, gasket retainers, door stiffeners, print pockets, door handles, lock rods, and other parts attached to the door or cover when you determine the size of the window kit you require.

Window Height inches (mm)	Window Width inches (mm)	Frame Height inches (mm)	Frame Width inches (mm)	Carbon Steel Part No.	Type 304 Stainless Steel Part No.	Type 316L Stainless Steel Part No.
5 (127)	3 (76)	8 (191)	6 (140)	WK0503C	WK05034	WK05036
9 (229)	6 (140)	12 (292)	8 (203)	WK0905C	WK09054	WK09056
13 (330)	3 (76)	16 (394)	6 (140)	WK1303C	WK13034	WK13036
13 (330)	8 (203)	16 (394)	11 (267)	WK1308C	WK13084	WK13086
17 (432)	6 (140)	20 (495)	8 (203)	WK1705C	WK17054	WK17056
17 (432)	11 (279)	20 (495)	14 (343)	WK1711C	WK17114	WK17116
23 (584)	15 (381)	26 (648)	18 (445)	WK2315C	WK23154	WK23156
29 (737)	19 (483)	32 (800)	22 (546)	WK2919C	WK29194	WK29196
35 (889)	23 (584)	38 (953)	26 (648)	WK3523C	WK35234	WK35236