

KL screw cover junction box



System accessories Page 531

Material:

- Type 304 stainless steel
- Enclosure: 18 ga (1.25 mm)
- Cover: 18 ga (1.25 mm)

Surface finish:

- Case and cover:
- Brushed

Protection rating:


- UL/cUL Type 4X
- (IP 66 to EN 60 529/10.91)
- CSA
- UL file #: E76082

Configuration:

- Enclosure
- Cover with foamed-on polyurethane gasket and quick-release cover screws, including plastic bushes

Detailed drawings:

Available at www.rittal.us

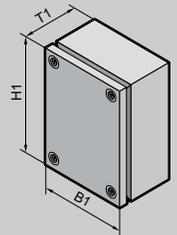

Depth: 3 - 5" (80 - 120 mm), Height: 6 - 8" (150 - 200 mm)

Height (H1) inches (mm)	PU	6 (150)	6 (150)	8 (200)	8 (200)	6 (150)	Page
Width (B1) inches (mm)		6 (150)	12 (300)	8 (200)	12 (300)	6 (150)	
Depth (T1) inches (mm)		3 (80)	3 (80)	3 (80)	3 (80)	5 (120)	
Part No.	1	1521.010	1522.010	1523.010	1524.010	1527.010	
Weight lb (kg)		3 (1)	4 (2)	4 (2)	5 (2)	5 (2)	

Accessories

Mounting panel	1	1560.700	1561.700	1562.700	1563.700	1560.700	635
Wallmount bracket	4	1594.000	1594.000	1594.000	1594.000	1594.000	628
Wall angle	1	2583.000	2583.000	2583.000	2583.000	2583.010	630
Support rails TS 35/7.5	10	2314.000	2316.000	2315.000	2316.000	2314.000	662
Cover retainer	3 pairs	1591.000	1591.000	1591.000	1591.000	1591.000	612
Cover hinge	6	1592.010	1592.010	1592.010	1592.010	1592.010	612

To order KL junction boxes in Type 316L stainless steel use the extension .520 (extended delivery times).

Depth: 5" (120 mm), Height: 8 - 12" (200 - 300 mm)

Height (H1) inches (mm)	PU	8 (200)	8 (200)	8 (200)	12 (300)	12 (300)	Page
Width (B1) inches (mm)		8 (200)	12 (300)	16 (400)	12 (300)	16 (400)	
Depth (T1) inches (mm)		5 (120)	5 (120)	5 (120)	5 (120)	5 (120)	
Part No.	1	1528.010	1529.010	1525.010	1526.010	1530.010	
Weight lb (kg)		5 (2)	7 (3)	8 (4)	9 (4)	11 (5)	

Accessories

Mounting panel	1	1562.700	1563.700	1564.700	1567.700	1568.700	635
Wallmount bracket	4	1594.000	1594.000	1594.000	1594.000	1594.000	628
Wall angle	1	2583.010	2583.010	2583.000	2583.000	2583.010	630
Support rails TS 35/7.5	10	2315.000	2316.000	2317.000	2316.000	2317.000	662
Cover retainer	3 pairs	1591.000	1591.000	1591.000	1591.000	1591.000	612
Cover hinge	6	1592.010	1592.010	1592.010	1592.010	1592.010	612

To order KL junction boxes in Type 316L stainless steel use the extension .520 (extended delivery times).