



Performance. Power.
Productivity.™

FinishPro® 33Mg

16 Ga. 20° Finish Nailer

The FinishPro 33Mg's magnesium body delivers an ultra light tool with SENCO dependability. The oil-free design, selective actuation, rear exhaust, rotating belt hook, and push-button air blower combine to provide a tool that will perform the toughest jobs while delivering professional results and comfortable operation.



Applications


Finish and trim, baseboard, cabinets, caskets, chair rail, decorative trim, door & window casing, furniture trim, paneling.

Features and Benefits

- Magnesium mainbody provides a durable and ultra light tool for comfortable extended use.
- Oil-free motor eliminates oil carryover onto the work surface protecting your hard work.
- Push-button air blower can dust off excess drywall powder, sawdust, dirt and debris from the work surface.
- Metal cylinder for increased durability.
- Tool-free depth-of-drive adjustment delivers perfectly countersunk fasteners into varying materials.
- Selectable trigger lets you control the fastening method with the flip of a switch.
- Rotatable exhaust and belt hook keeps dust and debris off the work surface while keeping your tool at the ready.
- Over-molded rubber grip, swivel plug and reload indicator will keep you working comfortably and efficiently throughout the day.
- Includes case, swivel plug and wrench.


Specifications

Item#	6F0001N
Trigger	Sequential Actuation
Reg. Operating Pressure	70-120 psi (4.8 - 8.3 bar)
Air Consumption (60 cycles per min.)	2.16 scfm
Air Inlet	1/4" NPT
Tool Weight	3.83 lbs (1.74 kg)
Height	11.5" (291 mm)
Length	12" (305 mm)
Width	3" (76 mm)
Fastener Capacity	110

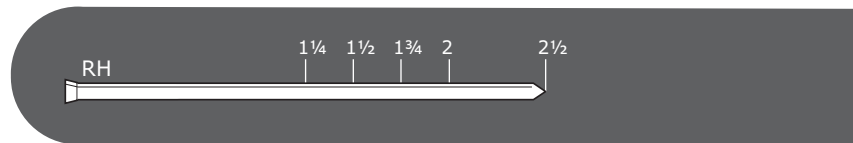

Fastener Specifications

Gauge	16
Fastener Range	1/4" - 2 1/2" (32mm - 65mm)
Finish	Galvanized
Collation	20° angles strip

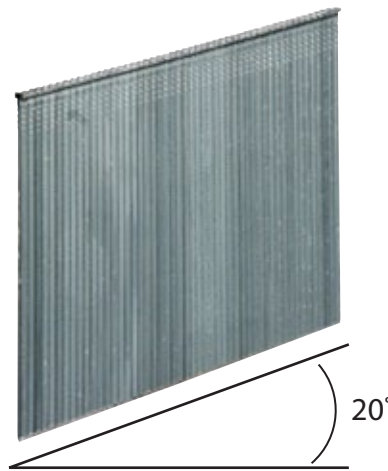

Available 16 Ga. 20° Angled Fasteners

Length	Item Code	Carton Count	Head	Point	Finish	Coating	Package
1/4	RH15EAA	2.M	T-head	Chisel	Galv	Sencote	Box
1/2	RH17EAA	2.M	T-head	Chisel	Galv	Sencote	Box
3/4	RH19EAA	2.M	T-head	Chisel	Galv	Sencote	Box
2	RH21EAA	2.M	T-head	Chisel	Galv	Sencote	Box
2 1/2	RH25EAA	2.M	T-head	Chisel	Galv	Sencote	Box

*NOTE: ONLY Fits 16 Gauge 20-Degree Finish Nailers

SENCO®

Performance. Power.
Productivity.™

FinishPro® 33Mg

16 Ga. 20° Finish Nailer Features



*Choose the right actuation model!

Sequential Actuation (also known as restrictive trigger or trigger fire) operates in the following sequence - depress the safety element at the nose of tool against the work surface then pull the trigger. After each fastener is driven, release the trigger and lift the tool off the work surface before starting the sequence again. This trigger is recommended and acceptable for most applications.

Contact Actuation (also known as dual action, bounce or bottom fire) operates in the following sequence- pull the trigger first and keep the trigger pulled while moving the tool along the work surface with a bouncing motion, depressing the safety element at the nose of the tool against the work surface where the fastener is to be driven. This trigger is recommended for use by trained professionals only in high production or volume applications.

Always read the Operators Manual and Safety Instructions with all tool to ensure proper use and safety precautions. For additional information on trigger systems and how SENCO will save you time, reduce costs and increase quality, call our toll-free Action Line: 800-543-4596, or visit our website at: www.senco.com