

# Super-Size AkroBins®

*Industry-standard large-capacity stacking bins*

- Heavy-duty, industrial-grade polymer bins securely stack atop each other
- Easy to carry with large handle molded onto back of bin



30289



30282



30293



30292 with 29304 Card Stock Holder



30281 with 40281 Divider



30284 with 41284 Dividers



30290 with 21283 Window

**COLORS**  
Red, Yellow, Blue, Clear




Super-Size AkroBins Model No.	Outside Dimensions (In.)			Inside Dimensions (In.)				Capacity/Quantity			Accessories						
	L	W	H	L	W	H	X	Max. Cap. per Bin	Stacking Cap./= Qty. Stacked	Ctn. Qty.	Width Dividers*	Length Dividers*	Divider Pkg. Qty. W L	Windows	Window Pkg. Qty.	Card Stock Holder	
30280	20	12 <sup>3</sup> / <sub>8</sub>	6	16 <sup>7</sup> / <sub>8</sub>	10 <sup>1</sup> / <sub>8</sub>	5 <sup>3</sup> / <sub>8</sub>	15 <sup>1</sup> / <sub>2</sub>	200 lbs.	40 lb./10	4	–	40280 (3)	–	2	21280	2	29304
30281	20	12 <sup>3</sup> / <sub>8</sub>	8	16 <sup>7</sup> / <sub>8</sub>	10 <sup>1</sup> / <sub>8</sub>	7 <sup>3</sup> / <sub>8</sub>	15 <sup>1</sup> / <sub>2</sub>	200 lbs.	50 lb./7	3	–	40281 (3)	–	3	21281	3	29304
30282	20	12 <sup>3</sup> / <sub>8</sub>	12	16 <sup>7</sup> / <sub>8</sub>	10 <sup>1</sup> / <sub>8</sub>	11 <sup>3</sup> / <sub>8</sub>	15 <sup>1</sup> / <sub>2</sub>	200 lbs.	60 lb./5	2	–	40282 (3)	–	1	21282	2	29304
30283	20	18 <sup>3</sup> / <sub>8</sub>	12	16 <sup>7</sup> / <sub>8</sub>	16 <sup>3</sup> / <sub>8</sub>	11 <sup>3</sup> / <sub>8</sub>	15 <sup>1</sup> / <sub>2</sub>	300 lbs.	150 lb./5	1	–	40282 (3)	–	1	21283	1	29304
30284	23 <sup>3</sup> / <sub>8</sub>	8 <sup>1</sup> / <sub>4</sub>	7	20 <sup>7</sup> / <sub>8</sub>	6 <sup>3</sup> / <sub>8</sub>	6 <sup>3</sup> / <sub>8</sub>	19 <sup>3</sup> / <sub>8</sub>	200 lbs.	150 lb./5	4	41284 (2)	40286 (1)	2	4	21284	4	29304
30286	23 <sup>3</sup> / <sub>8</sub>	11	7	20 <sup>7</sup> / <sub>8</sub>	9 <sup>3</sup> / <sub>8</sub>	6 <sup>3</sup> / <sub>8</sub>	19 <sup>3</sup> / <sub>8</sub>	200 lbs.	150 lb./5	4	41286 (2)	40286 (3)	2	4	21286	4	29304
30287	23 <sup>3</sup> / <sub>8</sub>	11	10	20 <sup>3</sup> / <sub>4</sub>	9	9 <sup>3</sup> / <sub>8</sub>	19 <sup>3</sup> / <sub>8</sub>	300 lbs.	150 lb./5	4	41287 (2)	40287 (3)	6	6	21287	4	29304
30288	23 <sup>3</sup> / <sub>8</sub>	16 <sup>1</sup> / <sub>2</sub>	11	20 <sup>3</sup> / <sub>4</sub>	14 <sup>3</sup> / <sub>8</sub>	10 <sup>3</sup> / <sub>8</sub>	19 <sup>3</sup> / <sub>8</sub>	300 lbs.	150 lb./5	1	41288 (2)	40287 (3)	6	6	21288	1	29304
30289	23 <sup>3</sup> / <sub>8</sub>	18 <sup>1</sup> / <sub>4</sub>	12	20 <sup>3</sup> / <sub>4</sub>	16	11 <sup>3</sup> / <sub>8</sub>	19 <sup>3</sup> / <sub>4</sub>	300 lbs.	150 lb./5	1	41289 (2)	40289 (3)	2	1	21289	1	29304
30290	29 <sup>1</sup> / <sub>4</sub>	18 <sup>3</sup> / <sub>8</sub>	12	26 <sup>3</sup> / <sub>8</sub>	16 <sup>3</sup> / <sub>8</sub>	11 <sup>3</sup> / <sub>8</sub>	24 <sup>3</sup> / <sub>4</sub>	300 lbs.	150 lb./5	1	–	40290 (3)	–	1	21283	1	29304
30292	29 <sup>3</sup> / <sub>8</sub>	11	10	26 <sup>3</sup> / <sub>4</sub>	9	9 <sup>3</sup> / <sub>8</sub>	25 <sup>3</sup> / <sub>8</sub>	300 lbs.	150 lb./5	4	41287 (2)	40292 (3)	6	6	21287	4	29304
30293	29 <sup>3</sup> / <sub>8</sub>	16 <sup>1</sup> / <sub>2</sub>	11	26 <sup>3</sup> / <sub>4</sub>	14 <sup>3</sup> / <sub>8</sub>	10 <sup>3</sup> / <sub>8</sub>	25 <sup>3</sup> / <sub>8</sub>	300 lbs.	150 lb./5	1	41288 (2)	40292 (3)	6	6	21288	1	29304

One color per carton: Specify Red, Blue, Yellow or Clear. Not recommended to hang on rack or panel systems. Order in carton quantities. \* ( ) = Max. # of divider slots per bin.

# Super-Size AkroBin® Shelving Systems

Super-Size AkroBin Wire Systems			Bin Dimensions (In.)			Shelf Dimensions (In.)			Quantity	
Model No.	Description	Colors	L	W	H	D	L	H	# of Bins	Shelves
AWS184830280	Wire Shelving w/ 30280 Bins	R, B, Y, SC	20	12¾	6	18	48	74	24	9
AWS184830281	Wire Shelving w/ 30281 Bins	R, B, Y, SC	20	12¾	8	18	48	74	18	7
AWS184830282	Wire Shelving w/ 30282 Bins	R, B, Y, SC	20	12¾	12	18	48	74	12	5
AWS184830283	Wire Shelving w/ 30283 Bins	R, B, Y, SC	20	18	12	18	48	74	8	5
AWS18485AB	Wire Shelving w/ 30280,281, 282, 283 Bins	R, B, Y, SC	See Above			18	48	74	4/3/4/4†	6
AWS24360284	Wire Shelving w/ 30284 Bins	R, B, Y, SC	23¾	8¼	7	24	36	74	28	8
AWS24360287	Wire Shelving w/ 30287 Bins	R, B, Y, SC	23¾	11	10	24	36	74	16†	6
AWS24360288	Wire Shelving w/ 30288 Bins	R, B, Y, SC	23¾	16½	11	24	36	74	12	3
AWS243605AB	Wire Shelving w/ 30287 & 30288 Bins	R, B, Y, SC	See Above			24	36	74	12/6†	3
AWS24361288	Wire Shelving w/ 30288 Bins	R, B, Y, SC	23¾	16½	11	24	36	63	10	3

Bin color code: R=Red, B=Blue, Y=Yellow, SC=Clear. Specify one bin color when ordering. †Bonus bins included.

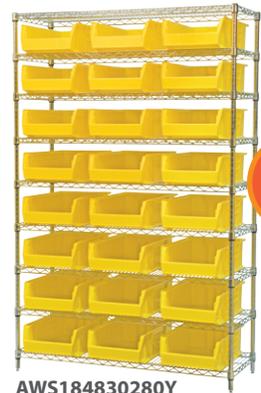

UP TO 2000 LBS.

AWS184830280Y



UP TO 6500 LBS.

AS3679292B

Super-Size AkroBin Steel Shelving Systems			Bin Dimensions (In.)			Shelf Dimensions (In.)			Quantity	
Model No.	Description	Color	L	W	H	D	L	H	# of Bins	Shelves
AS2479284	24" Shelving with 30284 Bins	B, R, Y, SC	23¾	8¼	7	24	36	79	32†	9
AS2479287	24" Shelving with 30287 Bins	B, R, Y, SC	23¾	11	10	24	36	79	24†	3
AS2479288	24" Shelving with 30288 Bins	B, R, Y, SC	23¾	16½	11	24	36	79	12	4
AS2479ASSORT	24" Shelving with 30287/30288 Bins	B, R, Y, SC	See Above			24	36	79	12/6	3
AS3679292	30" Shelving with 30292 Bins	B, R, Y, SC	29¾	11	10	30	36	79	24†	3
AS3679293	30" Shelving with 30293 Bins	B, R, Y, SC	29¾	16½	11	30	36	79	12	4
AS3679ASSORT	30" Shelving with 30292/30293 Bins	B, R, Y, SC	See Above			30	36	79	12/6	3

Bin color code: R=Red, B=Blue, Y=Yellow, SC=Clear. Specify one bin color when ordering. †Bonus bins included.

# Super-Size AkroBin® Dollies & Carts

Super-Size AkroBin Steel Dollies		Dimensions (In.)			Capacity/Qty.		
Model No.	Bin Compatibility	L	W	H	Casters	Capacity (lbs.)	Ctn. Qty.
RU843HR2018	30280, 30281, 30282 & 30283 Bins – Fits 1 wide	17¾	18¾	4¼	3" Polyolefin	900	1
RU843HR2918	30290 Bins – Fits 1 wide	26¾	18¾	4¼	3" Polyolefin	900	1
RU843TP2122	30286 & 30287 Bins – Fits 2 wide	20¾	21¾	4¼	3" Polyolefin	900	1
RU843TP2227	30292 Bins – Fits 2 wide	21¾	26¾	4¼	3" Polyolefin	900	1
RU843TP1721	30284 Bins – Fits 2 wide or 30288 Bins – Fits 1 wide	16½	20¾	4¼	3" Polyolefin	900	1
RU843TP1727	30293 Bins – Fits 1 wide	16½	26¾	4¼	3" Polyolefin	900	1
RU843TP1821	30289 Bins – Fits 1 wide	18½	20¾	4¼	3" Polyolefin	900	1

Bins sold separately.



UP TO 900 LBS.

RU843TP1721 with 30284R

Super-Size AkroBin Steel Carts		Dimensions (In.)			Capacity/Qty.		
Model No.	Bin Compatibility	L	W	H	No. of Handles	Capacity (lbs.)	Ctn. Qty.
R214CS1841	Six 30283 Bins	41	18	48	2	900	1
R214CS1859	Nine 30283 Bins	59	18	48	2	1350	1
R214CS1878	Twelve 30283 Bins	78	18	48	2	1500	1
R214CS2841	Six 30290 Bins	41	27½	48	2	900	1
R214CS2859	Nine 30290 Bins	59	27½	48	2	1350	1
R214CS2878	Twelve 30290 Bins	78	27½	48	2	1500	1
R216CS2236	Sixteen 30284 Bins or six 30286 Bins or six 30287 Bins or four 30288 Bins	35½	22¾	35	1	900	1
R216CS2836	Six 30292 Bins or four 30293 Bins	35½	28¾	35	1	900	1
R216CS2239	Four 30289 Bins	35½	22¾	39	1	900	1

Optional security bar available for all sizes. Bins sold separately.



UP TO 1500 LBS.

R214CS1878



1293 South Main Street, Akron, Ohio 44301 • Tel: 800.253.2467 • Fax: 330.761.6348 • sales@akro-mils.com  
 In Canada: 8028 Torbram Road, Brampton, Ontario L6T 3T2 • Tel: 877.877.9680 • Fax: 905.791.4084 • sales@buckhorncanada.com  
 Visit our website: [akro-mils.com](http://akro-mils.com) or [buckhorncanada.com](http://buckhorncanada.com)