

Imperial Shelving

Expandability

Attach any number of add-on units with "T" posts to create a continuous row of files

Pre-configured Units

Individual units are available in 76" and 88" heights and widths of 36" in letter and legal depth and 48" in letter depth only. Everything you need is packaged in one or two cartons.

Super Strong Framework

Steel shoulder rivets, combined with steel uprights and shelf supports, offer up to 400 lbs. capacity per shelf, depending on size.

Large, Adjustable Dividers with Backstop

Extra-large 7½" high by 10½" deep shelf dividers adjust in 2" increments and keep folders upright, while backstop keeps folders from falling off shelf.

Easy, Tool-Free Assembly

Imperial's unique Keyhole Slot design offers time saving snap-together assembly without tools.

No Sway Braces Required

Rigid framework requires no nuts, bolts or sway braces for obstacle-free access to files.

Adjustable Steel Shelves


Shelves adjust vertically in 1 ½" increments to fit your exact requirements.

Double Wall Uprights

Double wall post construction conceals the keyhole slots for a clean, attractive appearance. Welded steel panel between posts provides a clean look.

Protect Your Flooring

Carpet friendly molded PolyEthylene feet protect your flooring and carpet.

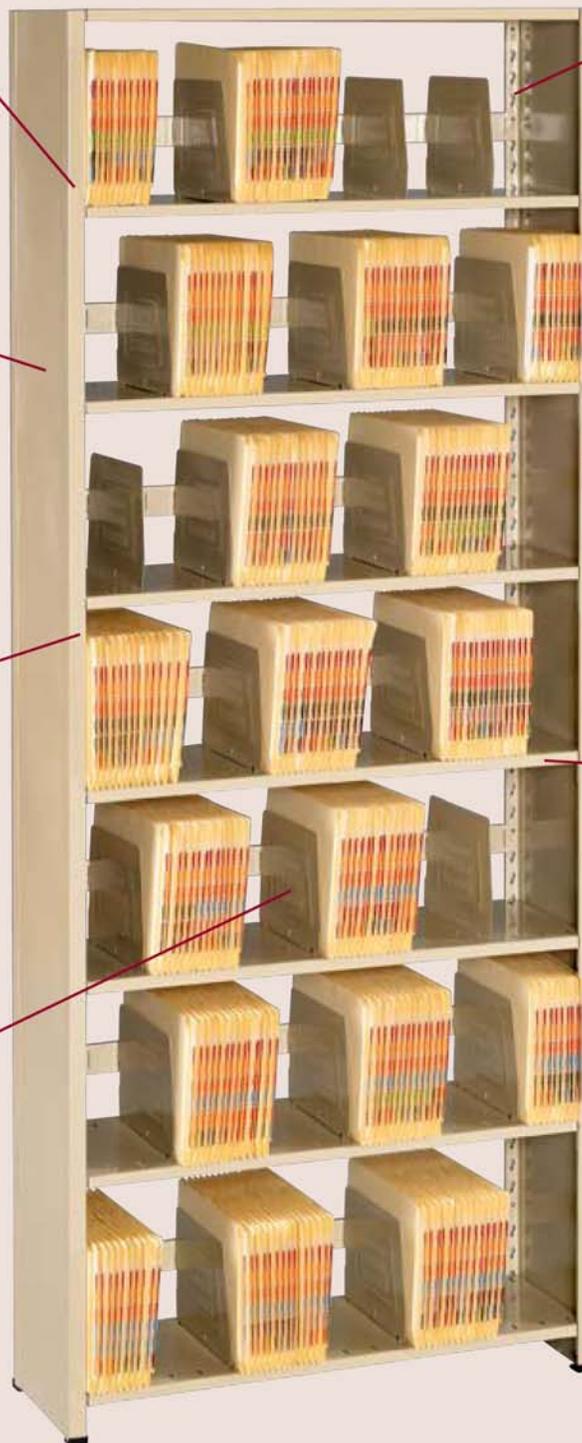

Imperial Shelving Systems

Imperial Shelving is the ideal solution for all your filing needs— especially in the office. Its unique space saving design saves up to 60% floor space when compared to conventional filing equipment.

Imperial Shelving can be used within the office environment anywhere tab filing is used. It makes files more visible when using a color-coding system, and more accessible by keeping them upright and orderly.

More Storage in Less Space



Imperial Shelving saves precious floor space by taking advantage of ample vertical space. Most applications result in space savings of up to 60% – at a fraction of the cost of conventional vertical or lateral drawer files.

Double Entry Available for Easy Access




Maximize space and efficiency in your office with Tennsco's Imperial Shelving Double Entry Unit. With a center stop, dividers can be placed where needed allowing full access on either side.

Easy Access & Visibility



Filing doesn't have to be a chore. Imperial's large dividers offer the right combination of end tab folder visibility and easy retrieval.

Looks Great in Any Décor

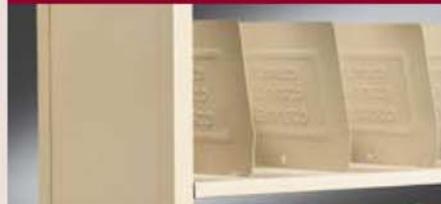

Imperial's unique construction offers a smooth, clean, attractive appearance. Its unique design conceals supports and keyhole slots, while the shelf lip covers the shelf support making it appropriate for any office application.

Reference Shelf Accessory



Create a convenient pull-out work space with our sliding Reference Shelf. (Note: Reduces filing space by 1".)

Easy Assembly



1. Place uprights opposite each other, held in place with a shelf support. Then, starting at the bottom, insert two additional shelf supports.





2. Lay a shelf over the bottom shelf supports. Then, moving upward, continue to add supports and shelves at each level.



3. Add back stops or center stops before inserting dividers. To add additional sections, use "T" uprights as common center posts and finish the row with "L" uprights. Add shelves as previously installed.

Keep Information Private and Secure

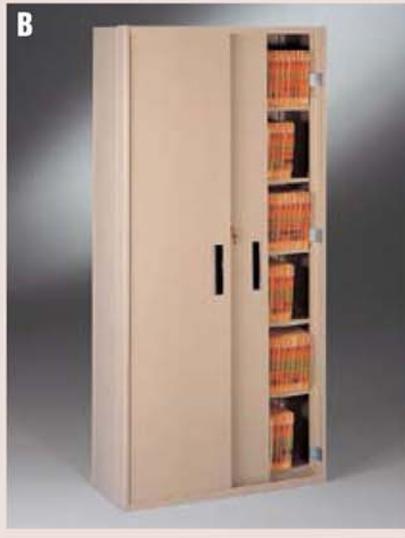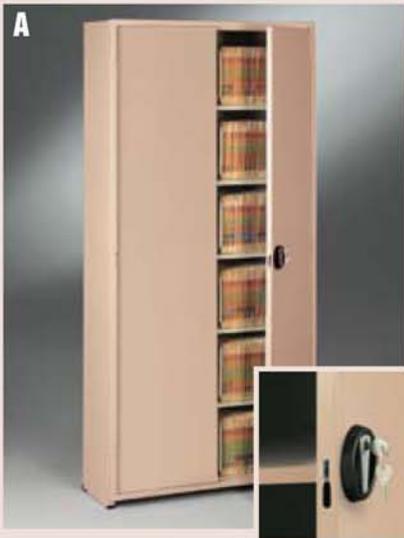

Tennsco offers three options to secure business and medical documents. Choose from (A) Hinged Style Locking Doors, (B) Sliding Locking Doors or (C) Rollup Locking Tambour Door. Door options can be added to new or existing installations. Each meets HIPAA* healthcare privacy regulations for safeguarding personal health information.

Cat. No.	Openings	W	D	H	Wt.
SINGLE ENTRY STARTER					
1276PC	6	36	12	76	117
127648PC	6	48	12	76	140
1576PC	6	36	15	76	125
1288PC	7	36	12	88	133
128848PC	7	48	12	88	156
1588PC	7	36	15	88	145
SINGLE ENTRY ADD-ON					
1276AC	6	36	12	76	108
127648AC	6	48	12	76	130
1576AC	6	36	15	76	114
1288AC	7	36	12	88	125
128848AC	7	48	12	88	147
1588AC	7	36	15	88	132
DOUBLE ENTRY STARTER					
2476PC	6	36	24	76	199
247648PC	6	48	24	76	247
3076PC	6	36	30	76	220
2488PC	7	36	24	88	229
248848PC	7	48	24	88	286
3088PC	7	36	30	88	256
DOUBLE ENTRY ADD-ON					
2476AC	6	36	24	76	177
247648AC	6	48	24	76	222
3076AC	6	36	30	76	205
2488AC	7	36	24	88	203
248848AC	7	48	24	88	257
3088AC	7	36	30	88	225

Cat. No.	W	D	H	Wt.
HINGED DOORS FOR 76" HIGH UNITS †				
LTHD-3676RH	36 1/8	76	56	
LTHD-4276RH	42 1/8	76	64	
LTHD-4876RH	48 1/8	76	81	
HINGED DOORS FOR 88" HIGH UNITS †				
LTHD-3688RH	36 1/8	88	63	
LTHD-4288RH	42 1/8	88	74	
LTHD-4888RH	48 1/8	88	84	
HINGED DOORS SPACER KITS				
HDFK-76	36	3	76	12
HDFK-88	36	3	88	13
SLIDING DOORS FOR 76" HIGH UNITS ††				
SD-3676-1	36 4 1/2	76	103	
SD-4276-1	42 4 1/2	76	121	
SD-4876-1	48 4 1/2	76	138	
SLIDING DOORS FOR 88" HIGH UNITS ††				
SD-3688-1	36 4 1/2	88	120	
SD-4288-1	42 4 1/2	88	139	
SD-4888-1	48 4 1/2	88	160	
TAMBOUR DOORS FOR 76" HIGH UNITS †††				
LTTD-3676	36	3	76	30
LTTD-4276	42	3	76	36
LTTD-4876	48	3	76	42
TAMBOUR DOORS FOR 88" HIGH UNITS †††				
LTTD-3688	36	3	88	36
LTTD-4288	42	3	88	42
LTTD-4888	48	3	88	48

Item No.	Description	Wt.
ACCESSORIES		
RSMB-12	Reference Shelf	9.3
RSMB-15	Reference Shelf	9.7
ISK-3612	Extra Shelf Kit	13.0
ISK-3615	Extra Shelf Kit	14.1
ISK-4812	Extra Shelf Kit	18.8

Cat. No.	W	D	H	Wt.
TWO PIECE BACKS				
LTBP-3676-2	36	—	76 7/16	18.6
LTBP-3688-2	36	—	88 7/16	21.0
LTBP-4876-2	48	—	76 3/16	25.0
LTBP-4888-2	48	—	88 7/16	29.0

- † Hinged Door Kit with recessed handle - fits single units and extends 2" from unit front, including handles; frame uses 2" vertical filing space.
- †† Sliding Door Kit fits single units and extends 3 3/4" from front of unit; door frame causes no loss of filing space.
- ††† Tambour Door fits single units and extends 2 7/8" from front of unit; no filing space is lost.

tennsco