

# 5400 SERIES

6000 WATT CONTACTORS  
WITH TURN-LOCK  
PHOTOCONTROL



## SPECIFICATIONS

**RECEPTACLE:** 3-prong turn-lock meets the requirements of EET NEMA.

**POWER CONSUMPTION:** Maximum 3 watts during daylight.

## APPLICATIONS

- For street lighting. Controls all lighting loads in excess of the capacity of the photoelectric control contacts.

## CONTACT RATINGS

CATALOG NO.	SWITCH	CONTACT RATING PER POLE
5403	DPST	3000W
5404	DPST	3000W
5404-3	DPST	3000W
5420	SPDT	1000W

## FEATURES

**HOUSING:** Outdoor NEMA Type 3R. Beige enamel finish. Two  $\frac{1}{2}$ " -  $\frac{3}{4}$ " combination KO in bottom.


**ENERGY SAVINGS:** Works with screw base CFLs and LED lamps.

## ORDERING INFO


CATALOG NO.	UPC CODE	PHOTOCONTROL INCLUDED	VOLTAGE 50-60Hz
5403	60009	5021M	105-130VAC
5404	60010	5024M	208-240VAC
5404-3	60011	5024M	277VAC
5420	60014	5021M	105-130VAC

## WIRING DIAGRAMS

120 VOLT CIRCUIT  
MODEL  
5403

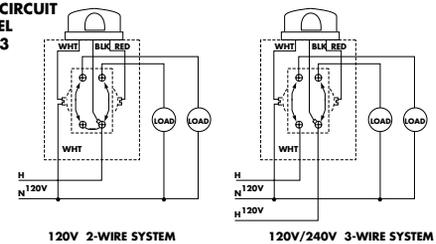


120 VOLT CIRCUIT  
MODEL  
5420

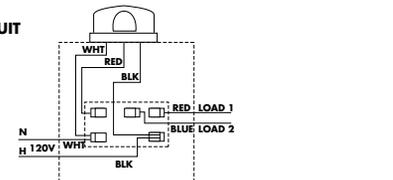


LOAD 1 CLOSES AT DUSK, OPENS AT DAWN  
LOAD 2 CLOSES AT DAWN, OPENS AT DUSK

277 VOLT CIRCUIT  
MODEL  
5404-3

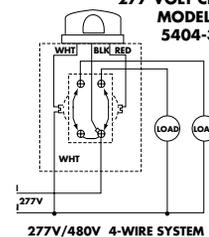

277V/480V 4-WIRE SYSTEM

208 or 240 VOLT  
CIRCUIT  
MODEL 5404

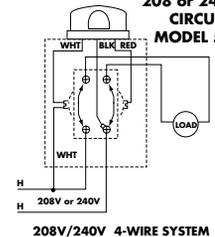

208V/240V 4-WIRE SYSTEM

## CASE DIMENSIONS

Add photoelectric control dimensions  
2" high x 3" diameter

