

**PD60**



## **Relaxed Fit Jean**

**Fabric:** 13.75 oz. Denim

**Blend:** 100% Cotton

**Care:** Home & Industrial Wash

**Features:** Two-needle contrast stitch styling, with felled outseams and seat seam. Relaxed fit. Five jean style pockets with antique brass rivets. One-piece waistband with button closure. Two patch hip pockets with decorative stitching and leatherette patch with logo. Scoop front pockets with watch pocket on right side. Brass ratcheting zipper with metal button closure. Traditional jean style back yoke. Soft stonewashed comfort and look.


**Colors:** Prewash (PW), Stonewash (SW), Black (BK)

# PD60

Watch pocket making this a true jean style pant →

Metal button and Brass ratcheting zipper →

Unfinished Hem on SW →

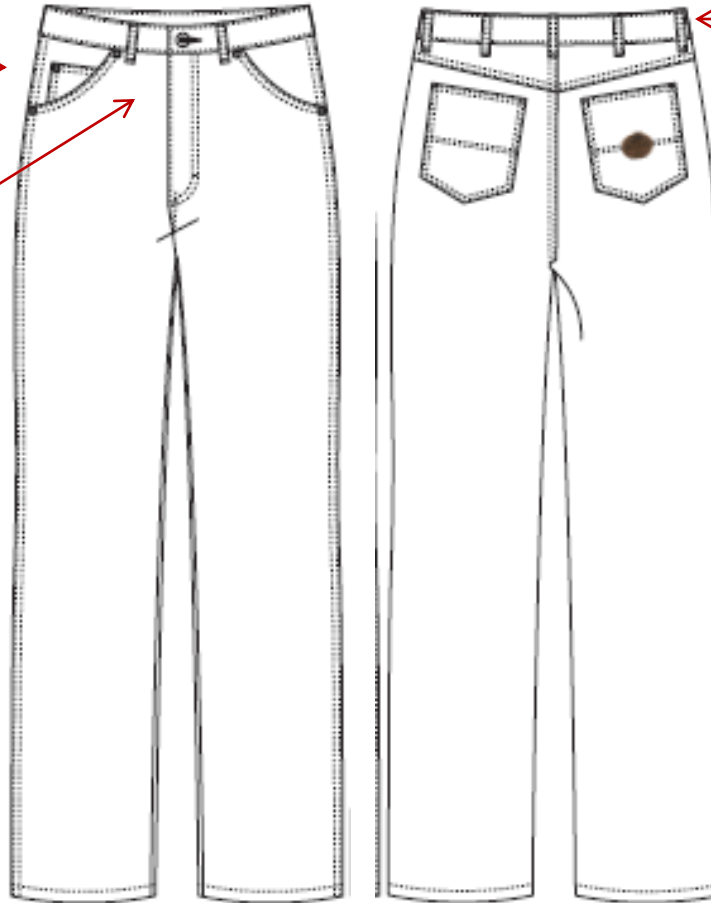

← 7 belt loops are attached for sizes up to 44, 9 for size 46 and up

This is a true relaxed fit jean. Classic rise sits at natural waist. Relaxed seat and thigh offer more room for mobility. Straight leg fits over the tops of work boots.

PD60 is soft and prewashed/ stonewashed for comfort and look