




Model # WL175MH

Part # 111102

175w Metal Halide Light

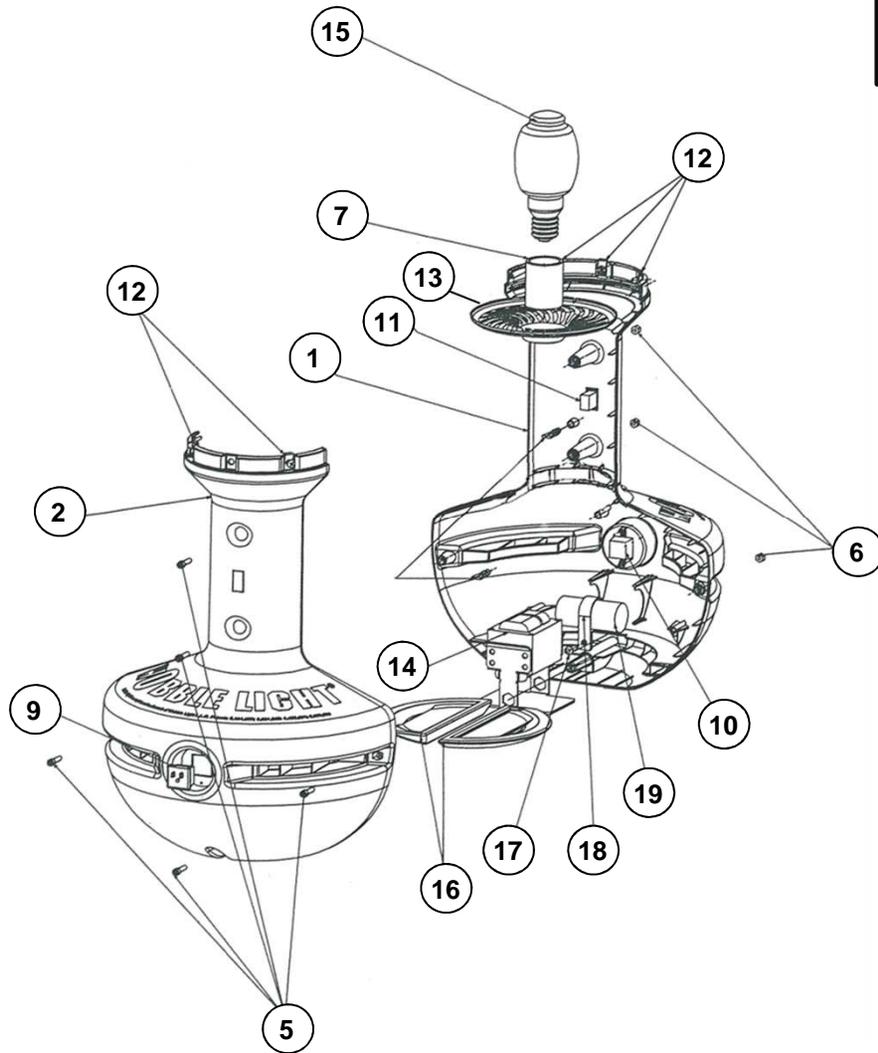

Specifications

Type = 175-watt Metal Halide
 Mean Lumens = 15,000
 Current = 1.6 Amps
 Voltage = 110VAC +/- 10%
 Weight = 23 lbs

Height = 36"
 Diameter (max) = 18"
 Color = yellow PMS-123C
 Lighting Range = 25-50 ft.
 Maximum units in series = 6

No.	Part #	Description	Qty.
1	11108087	Body Housing, ABS (front)	1
2	11108088	Body Housing, ABS (rear)	1
5	11108045	Screw, housing	5
6	11108040	Nut, housing	5
7	11102001	Socket, E39 mogul base	1
9	11101060	Plug, receptacle (female)	1
10	11101059	Plug, inlet (male)	1
11	11108066	Switch, sealed rocker	1
12	11108018	U-nut	5
13	111809	Shock disk	1
14	13101004*	Transformer w/bracket	1
15	111901	Bulb, 175W Metal Halide	1
16	11108038	Counterweight, 4.4-lb	2
17	11101504	Screw, capacitor clamp	1
18	11108101	Clamp, 1.5" (for 175MH cap)	1
19	11101003*	Capacitor, 10uF (175MH)	1
ns	111801	Dome & cap assembly	1
ns	11101008	PC Board	1
ns	11108110	Circuit breaker, 12A	1
ns	11101031	Fuseholder, in-line	1
ns	11101032	Fuse, 5A fast-blow ACG	1
*	11101012	Transformer Kit	--