

Dmed® **isis** 50 F - D14265000

TECHNICAL DATA

TREATMENT LIGHTS



FITTED WITH	1 x halogen lamp QT12 50 W - D68615000
LUMINOUS POWER	54 000 Lux / 0,8 m (31.5") 42 000 Lux / 1,0 m (39.4")
ILLUMINANCE FIELD 0,8 M	Ø 15 cm (5.9")
COLOUR TEMPERATURE	approx. 4300 K
WORK EQUIPMENT	electronic transformer
CONNECTED LOAD	120 V; 60 Hz
MAINS LEAD	approx. 3 m (118"); with hospital grade plug
LUMINAIRE BODY	polyamide & polycarbonate (PA & PC)
WEIGHT (NET)	approx. 17,0 kg (27.5 lbs)
POWER CONSUMPTION	approx. 65 W
USAGE	2-stages rocker switch (60/100 %), rocker switch (I/O)
TECHNOLOGY	2-pole primary
CLASS OF PROTECTION	II
NORMS	EN 60601-1, EN 60601-2-41
SPECIAL FEATURES	colour correction filter (4300 K), sterilisable grip
FASTENING	floor stand
ORDER NUMBER	D14265000 - pure white



LIGHT DISTRIBUTION

TECHNICAL DRAWING

measuring distance 0.8 m (31.5")

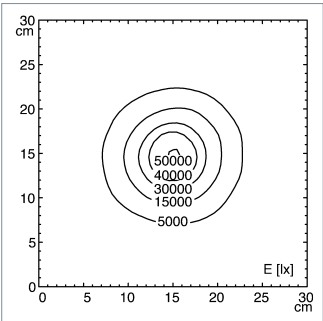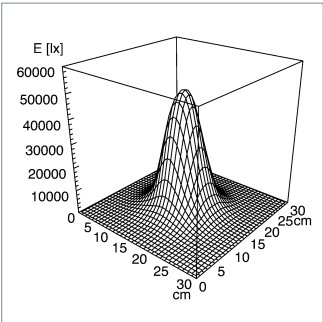

Dimensions in cm.

