



# ISIS™ SURGICAL AND DIAGNOSTIC LIGHT FOR VETERINARIANS

THE ISIS™ IS A HIGH-PERFORMANCE MINOR SURGERY LIGHT THAT PROVIDES SUPERIOR QUALITY WHILE FOLLOWING REGULATORY COMPLIANCE. ADVANCED ERGONOMIC DESIGN ALLOWS THE LIGHTWEIGHT ISIS™ TO MOVE EXACTLY AS NEEDED. IT OFFERS EXCELLENT LIGHTING FOR ANIMAL DIAGNOSTICS AND SURGERIES WITH ITS "STAY FOCUSED" FEATURE - NO NEED TO FOCUS ITS DEPTH OF FIELD (94"). SEE WHY VETS LIKE YOU ARE TURNING TO WALDMANN FOR QUALITY AND DEPENDABLE PROCEDURE LIGHTS!



APPROX. 80,000 LUX - 7400 FC at 24"  
45,000 LUX - 4200 FC at 1 METER

UNIQUE REFLECTOR TECHNOLOGY ALLOWS FOR EVEN, SHADOW-FREE LIGHTING



DRIFT-FREE ARM SYSTEM FOR EXCEPTIONAL POSITIONING

SMOOTH SURFACE ASSURES EASY CLEANING AND MAINTENANCE




STAYS COOL WITHOUT THE USE OF FANS

AUTOCLAVABLE HANDLE

SEE BACK FOR MORE DETAILS

# ISIS™ SURGICAL AND DIAGNOSTIC LIGHT FOR VETERINARIANS

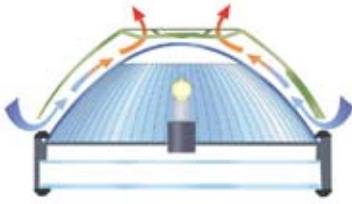


THE ISIS™ INNOVATIVE DESIGN ALLOWS HEAT TO DISSIPATE AWAY FROM THE ANIMAL WITHOUT THE USE OF FANS.




OUTER COVER FEATURES BUILT-IN MAGNETS FOR A QUICK OPENING AND SECURE CLOSING. A WRENCH IS INCLUDED AND ATTACHED FOR AN EASY LAMP CHANGE.


## SINGLE CEILING MOUNT

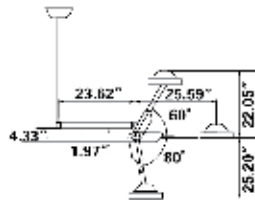

## FLOORSTAND

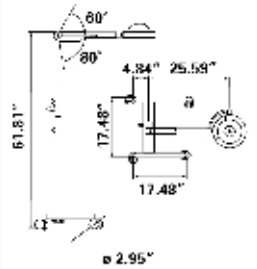

## DOUBLE CEILING MOUNT

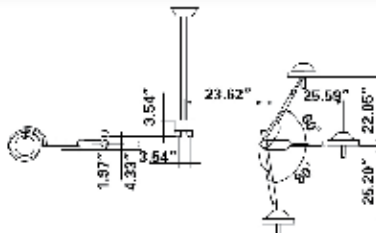

## WALL MOUNT

