



6100Series

Upgraded features



HolsterTop® with the new Lock-in Accessory System



Slip-resistant Traction-Tred® steps



New oversized, molded PROGUARD BOOTS™

★★★★★
300 lbs. LOAD CAPACITY

Includes User and Materials


Type IA Duty Rating





6100Series

- HolsterTop® with the Lock-in Accessory System
- Non-conductive fiberglass rails
- Internal spreaders
- Braces on bottom and top steps
- New oversized, molded PROGUARD BOOTS™ for added rail protection

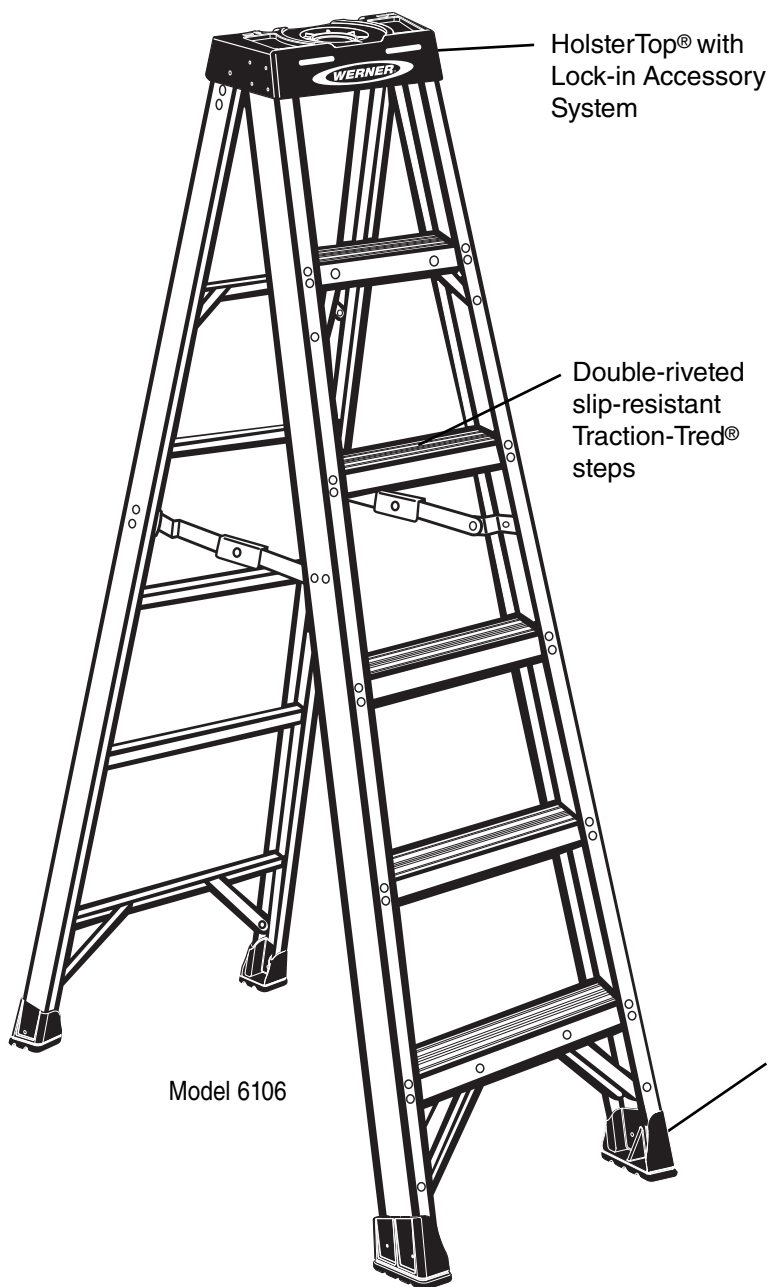

★★★★★
300 lbs. LOAD CAPACITY

Includes User and Materials

Type IA Duty Rating

SPECIFICATIONS

Model No.	Size	Approx. Width	Approx. Spread	Approx. Cu. Ft. Per Unit	Approx. Shipping Wt. Lbs.
6104	4'	19-5/8"	29-15/16"	2.56	15.0
6106	6'	22-5/8"	42-1/4"	4.46	21.0
6108	8'	25-5/8"	54-9/16"	6.76	30.0
6110	10'	28-5/8"	66-7/8"	13.02	35.5
6112	12'	31-5/8"	79-3/16"	17.27	44.0

DIMENSIONS

Top:	5-3/4" x 13"	Steps:	3" wide
Front Rails:	3-1/8" wide	Rear Rails:	1-7/8" wide
Front Flange:	1-3/16" wide	Rear Flange:	1-3/16" wide