


MODEL: HVL712

Mid-Back, Syncro tilt,
Tilt Lock, Pneumatic,
Polyurethane Arms

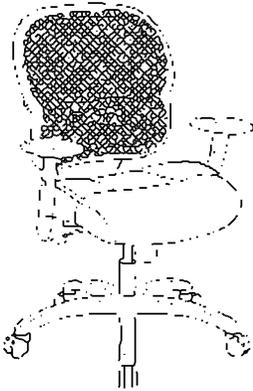

CHAIR SPECIFICATIONS

Max. Width.....	29-1/2"
Max. Depth.....	28-1/2"
Max. Height.....	41-3/4"
<u>Seat Size</u>	
Width.....	19-3/4"
Depth.....	18-1/2"
Usable Depth.....	18"
Height from Floor.....	18" - 22-1/4"
<u>Back Size</u>	
Width.....	20-1/2"
Height from Seat.....	20-3/4"
<u>Arm Size</u>	
Distance between arms....	18-1/8"
Height from floor.....	25"
Height from seat.....	7"
Width.....	4"
Length.....	11"

CONSTRUCTION

Caster.....	2" diameter black hooded dual wheel.
Base.....	Nylon base
Control.....	Black heavy gauge, synchro-tilt, tilt lock, 17-4 taper.
Seat.....	3" cut foam with black fabric upholstery.
Back.....	Black mesh.
Arm.....	Height adjustable arms with polyurethane arm rests.
Chair Weight.....	34 pounds.
Shipping Weight.....	39 pounds.
Shipped.....	Assembly Required
Shipping Size.....	13" wide x 27" deep x 26-1/2" high (XX cubic feet).
Special Features.....	A pneumatic gas cylinder is used for seating height adjustment of chair.
Note.....	All measurements are per BIFMA/CMD procedures.

Issue Date:	24-SEP-2010
Part Number:	53-8623

