


MODEL: HVL551

SWIVEL, TILT, TILT TENSION, HEIGHT ADJUSTABLE ARMS

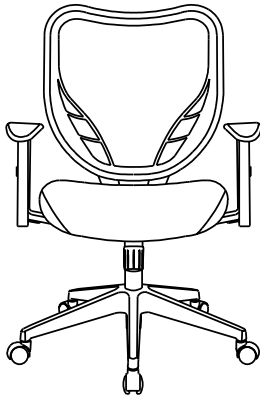

CHAIR SPECIFICATIONS

Max. Width..... 26
Max. Depth..... 29
Max. Height..... 39-3/4

Seat Size

Width..... 19-3/4
Usable Depth..... 17-1/4
Height from Floor..... 18-1/8 - 22-3/8

Back Size

Width..... 19-3/4
Height from Seat..... 19-7/8

Back Lumbar

Height..... 8-1/2

Arm Size

Distance between arms.... 19
Height from floor..... 26 - 32-1/2
Height from seat..... 8-3/8 - 11
Width..... 3-3/4
Length..... 10

CONSTRUCTION

- Caster..... Black hooded 2-1/2" diameter dual wheel.
- Optional Caster..... See List Pricer.
- Base..... Black 5 leg injection molded plastic.
- Control..... Black heavy gauge steel, swivel tilt, tilt tension, tilt lock, 17-4 taper.
- Seat..... 14MM thick, 7-ply plywood, 3" thick urethane foam cushion.
- Back..... Plastic injection molded, mesh fabric..
- Arm..... Black injection molded, built in height adjustment and plastic arm pad..
- Upholstery..... See List Pricer.
- Chair Weight..... 29 pounds.
- Shipping Weight..... 34 pounds.
- Shipped..... Disassembled, assembly required. See assembly instructions for details.
- Shipping Size..... 25.6" wide x 12.6" deep x 25.6" high
(4.78 cubic feet).
- Flammability
Rating..... Furnished upon request by The HON Company Customer Service.
- Special
Features..... A pneumatic gas cylinder is used for seating height adjustment of chair.
- Note..... All measurements are per BIFMA/CMD procedures.

Issue Date:	31-MAR-2011
Part Number:	54-3147

