



Housing & Bracket Kits



The *inMotion* CHP series housing kits all include a side opening housing and the inCHPB feed through wall mount bracket. This indoor /outdoor housing offers security and environmental protection against the elements.

The side opening provides easy access for the installer with the option of factory installed 24VAC heater and blower help to maintain stable working temperatures while the feed-through mounting bracket simplifies the cable wiring into the housing.

The inCHP series is an ideal choice for your security applications requiring the housing of a traditional style "box" camera and lens..

Features:

inCHP15/inCHPHB


- Indoor/Outdoor Housing
- Poly-Carbonate Construction
- Side Opening Lid
- 24VAC Powered*
- Thermostatic Heater and Blower*

inCHPB

- Die Cast Wall Mount
- Universal Knuckle Joint
- Cable Feed-Through for Housing

*inCHP15HB only

General	Construction	Polycarbonate
	Weight	4.2lbs (1.90kg)
	Latch	Top mounted screws
	Environment	Indoor/Outdoor -10°F to 120°F (-23° C to 49° C)
Mechanical	Maximum Camera Size	9.8" x 3.75" x 3.14" (249 x 95 x 79mm)
	Viewing Window Area	3" Round
	Cable Entry	Bottom (Cable managed through mount)
	Housing Dimensions	15" x 6" x 5.5" (381 x 153 x 140mm)
	Bracket Dimensions	8.4" x 3.1" x 4.7" (214 x 79 x 120mm)
Electrical (inCHP15HB only)	Heater	Thermostatically controlled On at 59°F/15°C. Off at 77°F/25°C
	Blower	Thermostatically controlled On at 99°F/37°C. Off at 83°F/28°C
	Power Requirements	24VAC
	Heater	6VA (0.25A)
	Blower	1.68VA (0.14A)
Order Codes	Unheated version: Heater/Blower version:	inCHPKIT inCHPHBKIT

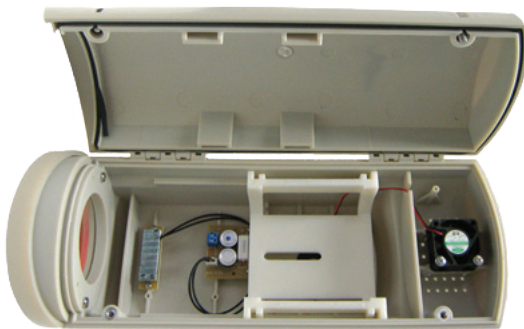

inMotion International reserve the right to amend specifications and design without prior notice