

# 09 12 240

## Lineman's Pliers

American style




- solid construction for heaviest strain; universally applicable
- high transmission ratio for easy cutting
- requires 40% less effort compared with conventional combination pliers thanks to optimised transmission ratio
- ergonomically optimized handle shape for firm contact to the hand and fatigue reducing operation
- particularly effective crosswise serrated gripping zone in the jaws - for strong gripping and pulling
- additional gripping zone below the articulated joint for powerful leverage and pressing performance
- with cutting edges for soft and hard wire
- cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Vanadium electric steel; forged, oil-hardened
- with cable puller in the joint gap
- with universal mandrel crimping point under the joint


<b>Product Number</b>	09 12 240
<b>EAN</b>	4003773071969
<b>Pliers</b>	black atramentized
<b>Head</b>	polished
<b>Handles</b>	with multi-component grips
<b>medium hard wire Ø mm</b>	4,6
<b>hard wire Ø mm</b>	3
<b>Length mm</b>	240
<b>Net weight g</b>	470




Gripping zone below the joint for powerful leverage

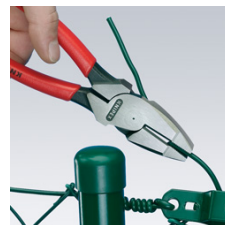


Crosswise serrated gripping zone for firm gripping and pulling, e. g. for fence construction

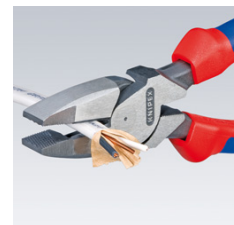

Long cutting edges for cutting flat cables

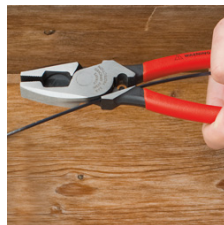

09 11/12 240: cable pulling aid in the joint gap

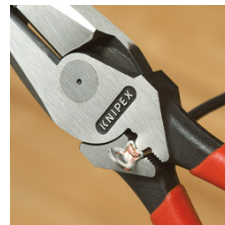

09 11/12 240: universal mandrel crimping area under the joint

technical change and errors excepted

