


BODY SHOP MASKING TAPE

OUTDOOR
30
DAYS



BS-002

Discover our AmTape® Body Shop Masking Tape, a professional-grade solution designed for routine automotive masking tasks. Made with flexible semi-crepe paper and a high-tack, acrylic-based adhesive, it delivers reliable performance for general refinishing, sanding prep, and collision repair. An excellent choice for high-turnover jobs where speed and value matter.

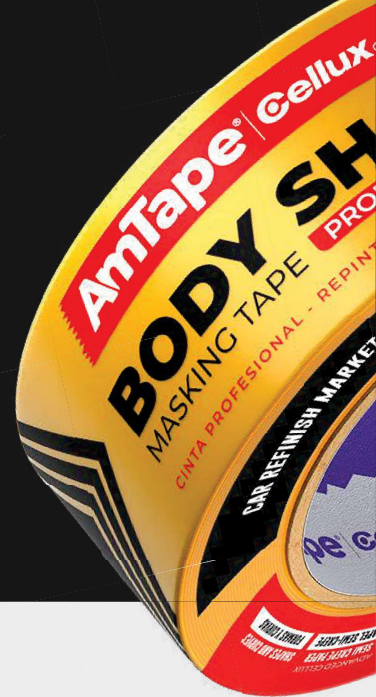

Surfaces

Metal, rubber, glass, and plastic.

1 Uses

- Masking for primer and basecoat applications.
- Quick-turnaround body repair and repainting.
- Protecting moldings, trim, and glass during sanding or polishing.
- Ideal for car dealerships, garages, and collision repair shops.

3 Technical Data

Backing	Semi-crepe paper	
Adhesive	Water base Acrylic	
UV Resistance	30 days	
Physical properties	Standard	Metric
180° peel force	8-11 oz/in	2.2 - 3-2 N/25mm
Tensile strength	17-20 lbs/in	30-35 N/10mm
Temperature 30min	248°F	120 °C

5 Size

Width	Length
0.47" (12mm)	60yd (54.8m)
0.70" (18mm)	60yd (54.8m)
0.94" (24mm)	60 yd (54.8m)
1.41" (36 mm)	60 yd (54.8m)
1.88" (48 mm)	60 yd (54.8m)
2.83" (72mm)	60 yd (54.8m)

2 Features

- Conformable semi-crepe paper for curved surfaces.
- Strong adhesion on metal, rubber, glass, and plastics.
- Clean removal without residue.
- Easy to tear by hand.
- Cost-effective for high-volume daily use.
- High-temperature resistant: 248 °F / 120 °C for 30 minutes.

4 Storage Conditions

- Store in a cool, dry place, away from direct sunlight and excessive humidity to maintain film performance. For best results, use this product within one year from the date of production.

6 How to use

- Ensure the surface is clean, dry, and dust-free before application.
- Apply the tape with firm, even pressure for optimal adhesion.
- Remove within 30 minutes if exposed to high temperatures (248 °F / 120 °C).
- For best results, peel off slowly at a 45-degree angle to avoid surface damage.

7 Logistic Information

SKU	Size / Description	Cases/pallet	Roll/Case
BS002-12060PK1	0.47 " (12mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	144	48
BS002-18060PK1	0.70 " (18mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	144	32
BS002-24060PK1	0.94 " (24mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	144	24
BS002-36060PK1	1.41 " (36mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	144	16
BS002-48060PK1	1.88 " (48mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	112	12
BS002-72060PK1	2.83 " (72mm) x 60 yd (54.8m) YELLOW BODY SHOP Masking Tape OUTDOOR 30-Day UV-Protected - Individually packaged	112	8

WE STICK STRONG