



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Gates LED Sconce GATS Series

Features

Sleek contemporary styling with die-cast metal backplate.
Ideal use in hallways, entrances or anywhere general lighting is needed.
Provides lighting in residential, commercial and hospitality applications.
Fixture mounts to standard junction box (not included).

Construction

Back plate is die-formed of 22-gauge steel. Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

Finish

Black, Satin Brass or Satin Nickel.

Diffuser

White acrylic diffuser.

Electrical

Input 120 VAC 60 HZ.
Compatible with residential (TRIAC/ELV) dimmers.

LED

Integrated LED modules capable of producing:
8W = 500 delivered lumens
Adjustable 2700K, 3000K, 3500K, 4000K, 5000K (CCT).
Rated for 50,000 Hrs., 90 CRI.

Certification


All fixtures are cETLus listed for indoor damp locations.
ADA Compliant
Title 24/JA8 Compliant

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

Specifications and dimensions

subject to change without notice.

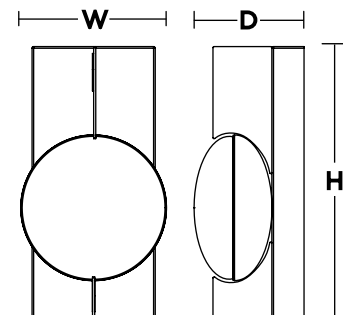

Ordering Information:

Black	Satin Brass	Satin Nickel	LED	Delivered Lumens	Adjustable CCT	H	W	D
GATS0610LAJD1BK	GATS0610LAJD1SB	GATS0610LAJD1SN	8W	500	2700K/3000K/3500K/4000K/5000K	10"	5-1/2"	4"