


# HOSPITAL GRADE RECEPTACLES

## Heavy-Duty Hospital Grade Tamper-Resistant Receptacles 15 & 20A, 125V

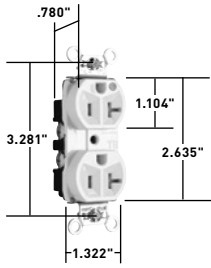


TR8300HW

### Features

- Dual mechanical shutter system to help prevent insertion of foreign objects.
- .032-inch thick, brass, triple-wipe power contacts for lasting retention.
- Easily accessible break-off line contact connecting tab for split circuit wiring.
- Terminal compartments isolated from each other for positive conductor containment.
- Corrosion-resistant, zinc-plated steel strap is locked in.
- Internal screw-pressure-plate back wire and side wire line terminals accept #14 – #10 AWG copper or copper-clad conductors.
- High strength thermoplastic back body.
- Two back wire holes for more wiring flexibility.
- Auto-ground clip assures positive ground.
- Compact design for easy installation.
- Tri-drive terminal and mounting screws.

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.			UL498	FSUL WC596	C22.2 No. 42
<b>HOSPITAL GRADE TAMPER-RESISTANT DUPLEX RECEPTACLES BACK AND SIDE WIRE</b>							
TR8200HI	15	125	Ivory	5-15R	•	•	•
TR8200HW	15	125	White	5-15R	•	•	•
TR8200HLA	15	125	Light Almond	5-15R	•	•	•
TR8200HGRY	15	125	Gray	5-15R	•	•	•
TR8200HRED	15	125	Red	5-15R	•	•	•
TR8200HBK	15	125	Black	5-15R	•	•	•
TR8300HI	20	125	Ivory	5-20R	•	•	•
TR8300HW	20	125	White	5-20R	•	•	•
TR8300HLA	20	125	Light Almond	5-20R	•	•	•
TR8300H	20	125	Brown	5-20R	•	•	•
TR8300HGRY	20	125	Gray	5-20R	•	•	•
TR8300HRED	20	125	Red	5-20R	•	•	•
TR8300HBK	20	125	Black	5-20R	•	•	•
TR8300HBL	20	125	Blue	5-20R	•	•	•


### 2 Pole, 3 Wire

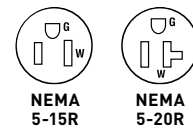

STRAIGHT BLADE RECEPTACLES

# HOSPITAL GRADE RECEPTACLES

## Extra Heavy-Duty Hospital Grade Receptacles 15 & 20A, 125V; 20A, 250V

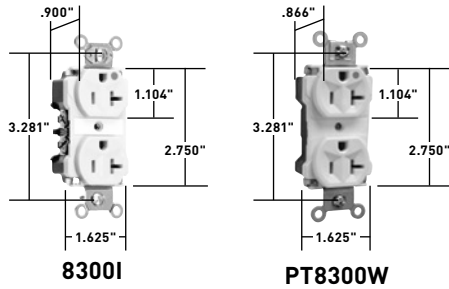


### Features

- One-piece nickel-plated brass mounting strap with integral ground.
- Strap tabs wrap around and lock down on face to prevent strap from separating from face and back body.
- Two drive screws anchor strap to back body and face.
- Exclusive patented feature, circuit label on face allows permanent circuit identification.
- .040 inch thick, nickel-plated brass, triple-wipe power contacts for lasting retention.
- Easily accessed break-off, line-contact connecting tab for fast, easy split-circuit wiring.
- Impact-resistant nylon face and back body.
- Oversized #10 deep tri-drive head brass terminal and ground screws.
- Exclusive patented feature, external screw-pressure-plate back wire clamp on ground terminal for faster, easier installation.
- External nickel-plated screw-pressure-plate back wire clamps with #10 brass terminal screws for visual assurance of a good connection.
- Line terminals accept #14 – #10 AWG stranded or solid copper clad conductors.
- Auto-ground clip assures positive ground.
- Built-in connector features large brass terminal blades to ensure consistent, reliable electrical connections.
- Crimped and welded contacts.
- Ultrasonically welded polycarbonate connector housing secures terminations and conductors in a UL Listed, finger safe housing.
- Large brass contacts snugly terminate on device blade terminals.
- Pre-stripped connector leads fasten to conductors, easier than standard pigtailed.
- Auto-ground clip assures positive ground.
- **PlugTail devices** install up to 5 times faster than traditional.

### PlugTail® Features Only

- .036 inch thick, brass, triple-wipe power contacts for lasting retention.
- Plated steel wrap-around strap design for maximum durability and corrosion resistance.
- No exposed terminals create a finger safe application before, during, and after installation.

CATALOG NUMBER	PLUGTAIL CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
		A.	V.			UL <sup>US</sup> UL498	FSUL WC596	C22.2 No. 42
<b>DUPLEX RECEPTACLES</b>								
8200I	PT8200I	15	125	Ivory	5-15R	•	•	•
8200W	PT8200W	15	125	White	5-15R	•	•	•
8200		15	125	Brown	5-15R	•	•	•
8200GRY	PT8200GRY	15	125	Gray	5-15R	•	•	•
8200BK	PT8200BK	15	125	Black	5-15R	•	•	•
8200RED	PT8200RED	15	125	Red	5-15R	•	•	•
8200LA	PT8200LA	15	125	Light Almond	5-15R	•	•	•
	PT8200BL	15	125	Light Almond	5-15R	•	•	•
8300I	PT8300I	20	125	Ivory	5-20R	•	•	•
8300W	PT8300W	20	125	White	5-20R	•	•	•
8300	PT8300	20	125	Brown	5-20R	•	•	•
8300GRY	PT8300GRY	20	125	Gray	5-20R	•	•	•
8300BK	PT8300BK	20	125	Black	5-20R	•	•	•
8300RED	PT8300RED	20	125	Red	5-20R	•	•	•
8300LA	PT8300LA	20	125	Light Almond	5-20R	•	•	•
	PT8300BL	20	125	Light Almond	5-20R	•	•	•
8800I		20	250	Ivory	6-20R	•	•	•
8800W		20	250	White	6-20R	•	•	•
8800		20	250	Brown	6-20R	•	•	•
8800GRY		20	250	Gray	6-20R	•	•	•
8800BK		20	250	Black	6-20R	•	•	•
8800LA		20	250	Light Almond	6-20R	•	•	•
8800RED		20	250	Red	6-20R	•	•	•

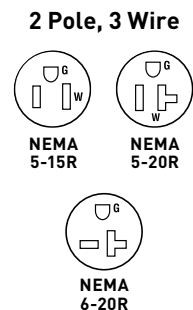

For Bulk Packaging Solutions consult factory.

All devices listed on this page conform to NEMA WD-1 and WD-6.