




KS31, Split Bolt Connector, Run/Tap: 1/0 AWG Str-350 kcmil

By Burndy
Catalog # [KS31](#)

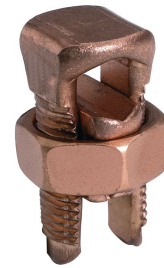

Copper Split Bolt, Cu: 1/0 AWG (Str)-350 kcmil (Run & Tap)

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Cables

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	<ul style="list-style-type: none"> • Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	<ul style="list-style-type: none"> • UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	<ul style="list-style-type: none"> • UL 486A • UL486B
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	5
Conductor - Rebar Size Range	5
Conductor - Copper Str Run Range	1/0 STR - 350 KCMIL
Conductor - Copper Str Run	<ul style="list-style-type: none"> • 1/0 • 2/0 AWG • 3/0 AWG • 4/0 AWG • 250 kcmil • 300 kcmil • 350 kcmil

Conductor - Copper Solid Run Range 1/0 -350 kcmil

- Conductor - Copper Solid Run
- 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil

Conductor - Copper Solid Tap Range 1/0 -350 kcmil

- Conductor - Copper Solid Tap
- 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil

Conductor - CopperWeld Str Tap Range 19 #8

Conductor - CopperWeld Str Tap 19 #8

Conductor - CopperWeld Str Run Range 19 #8

Conductor - CopperWeld Str Run 19 #8

- Conductor Type
- CU C Solid-Run
 - CU C Str-Run
 - CU Weld C Solid-Run
 - CU Weld C Str-Run
 - CU C Str-Tap
 - CU Weld C Solid-Tap
 - CU Weld C Str-Tap
 - CU C Solid-Tap

Conductor - Copper Str Tap Range 1/0 STR - 350 KCMIL

- Conductor - Copper Str Tap
- 1/0
 - 2/0 AWG
 - 3/0 AWG
 - 4/0 AWG
 - 250 kcmil
 - 300 kcmil
 - 350 kcmil

Configuration

Connector Type Split Bolt

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	64 mm
Width	1.41 in
Dimension - Width fraction	1-41/100 in
Dimension - B Length fraction	1-1/4 in
Dimension - Width mm	36 mm
Dimension - Width inch	1.41 in
Dimension - B Length inch	1.25 in
Dimension - Cross Flats inch	1.70 in
Dimension - Length Overall inch	2.6

Force Related

Installation Torque	650 in
Recommended in-lb	

General

Trade Name	SERVIT®
Plated	N
Sub Brand	SERVIT
UPC	781810014257
Type	KS
Material	Copper
Plating Type	Unplated
UPC 12 Digit	781810014257
UPC 14 Digit GTIN	00781810014257

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)



A Hubbell brand