

# 3.1

## NEMA Manual Starters

### Starters and Switches




#### Product Selection

##### When Ordering Specify

- Catalog number of manual motor switch

 
3

#### Manual Motor Switches without Overload


	Maximum Horsepower Ratings				Open	NEMA 1 Enclosed
	120V	240V	480V	600V		
<b>Two-Pole B230AN</b>	<b>Two-Pole—Manual Motor Switches</b>					
	2	5	—	—	B230AN	B230AG
<b>Two-Pole NEMA 1 Enclosure B230BG</b>	2	5	10	15	B230BND	B230BGD
						
<b>Three-Pole B330AN</b>	<b>Three-Pole—Manual Motor Switches</b>					
	3	7-1/2	15	20	B330AND	B330AGD

#### Wiring Diagrams

##### B230AN



##### B230BN

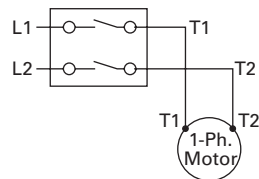

##### B330AN

