

Rigid Elbows
15° - Galvanized Steel

Features

- Low conductivity, high corrosion resistance
- Smooth defect free interior and exterior

Applications


- For a secure connection to Rigid conduit; bend enables directional changes in conduit

Standard Material

- Galvanized steel



UL 797 and ANSI C80.3
Federal Specification WW-C-563

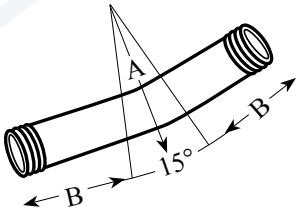

Catalog Number	UPC	Size	Unit Carton	Ship Case	Weight/ Case	(A) Min. UL Radius	(B) Straight Leg Each End
6415	83917	1-1/4"	---	20	32	7.25	2.781
6515	83918	1-1/2"	---	15	34	8.25	2.781
6615	83919	2"	---	10	33	9.50	2.781
6715	83920	2-1/2"	1	50	350	10.50	3
6815	83921	3"	1	35	350	13	3.125
6915	83922	3-1/2"	1	35	455	15	3.281
7015	83923	4"	1	35	595	16	3.375