

16 AWG

GC014



QUICKLY CONNECT. BATTERY CLAMPS WITH M10 EYELETS.

DESIGNED FOR
NOCO genius
BATTERY CHARGERS AND MAINTAINERS.

COMPATIBLE WITH ALL NEW GENIUS:

GENIUS1

GENIUS2

GENIUS5

GENIUS10

GENIUS2X2

GENIUS2X4

+ PREVIOUS NOCO G SERIES:

G750

G7200

G1100

G4

G3500

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co



DUAL PURPOSE

CLAMPS OR EYELETS.

The GC014 battery clamps are compatible with the X-Connect on Genius Chargers. Attach to the battery with the micro clamps for temporary connections or permanently mount the eyelets to the battery to quickly plug in your Genius battery charger for daily charging and battery maintenance.



20A MICRO BLADE FUSE

Built-in 20A fuse protection for increased safety. The 20A fuse provides equal protection while being 45% smaller than the previous NOCO 10A Fuse.



WIDE SPAN


Fits battery terminals of any shape.

M10 EYELETS

10mm Diameter



WHAT'S IN THE BOX

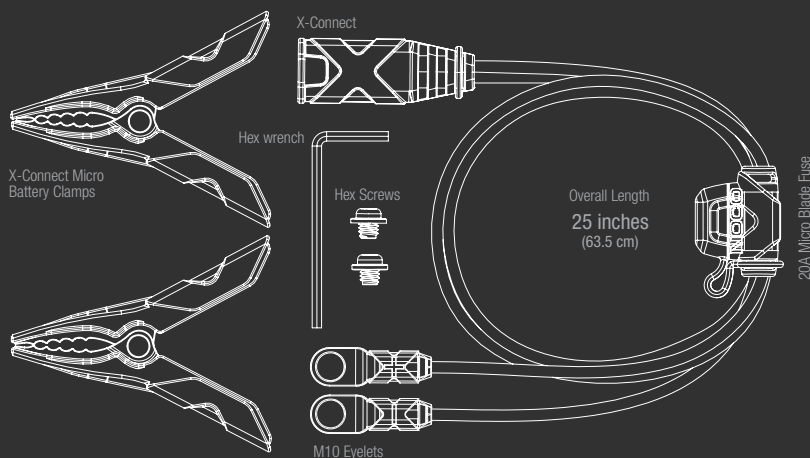

TECHNICAL SPECIFICATIONS

WIRE SIZE:	16 AWG
INPUT:	X-Connect Female
FUSE:	20 Amp Micro Blade
CABLE LENGTH:	21 in (53.4cm)
WEIGHT:	0.53 lbs (0.24kg)
VOLUMETRICS:	Retail Packaging: Dimensions: 3.2" x 2.0" x 5.1" Weight: 0.57 lbs UPC: 0-46221-11006-7 Inner Carton: Dimensions: 5.4" x 2.3" x 3.9" Weight: 0.64 lbs
	Master Carton: Dimensions: 7.3" x 5.7 x 7.9" Weight: 4.23 lbs Quantity: 6 UCC: 20046221110061 Units Per Pallet: 1,260 Units

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co