

2/0 AWG

GBC004
GBC005



GBC004
24"

GBC005
72"

COMMERCIAL-GRADE JUMP STARTS.
BOOST MAX™ BATTERY CLAMPS.

COMPATIBLE WITH:

GB500+



NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

SECURELY CONNECT. HIGHLY-CONDUCTIVE CAMLOCKS.

GBC004 and GBC005 Boost MAX™ Battery Clamps are compatible with the camlock connectors on Boost MAX GB500+.

2/0 AWG SILICONE WIRE.
POWERFUL CURRENT TRANSFER.

MULTI-LAYERED TEETH.
FOR IMPROVED TERMINAL CONTACT.

MAXIMUM CONDUCTIVITY.


Designed to efficiently transfer maximum current flow with minimal power loss. Made from durable, heat stabilized 2/0 AWG silicone wire that maintains its flexibility in cold weather environments. Multi-layered clamp teeth allow for more contact points to be on the battery terminal's surface.

REACH AND CONNECT.


The 72-inch (182cm) reach of the GBC005 clamps allows for ease of use, for situations when carrying the GB500+ is not convenient.

DIMENSIONS.

GBC004

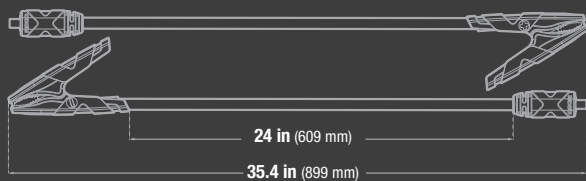

GBC005

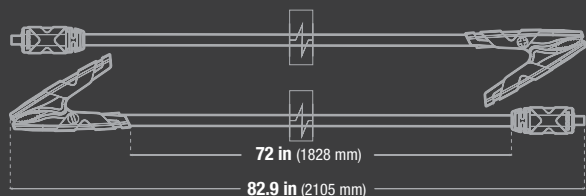

TECHNICAL SPECIFICATIONS

COMPATIBILITY: BOOST MAX GB500+

GBC004 WEIGHT: 5.51 lbs (2.49kg)

GBC005 WEIGHT: 7.41 lbs (3.36kg)

INPUT: Boost Female Connector

VOLUMETRICS:	GBC004	GBC005
	Inner Carton: Dimensions: 15.28"x12.52"x2.76" Weight: 5.95 lbs UPC: 0-46221-18006-0	Inner Carton: Dimensions: 3.35"x10.04"x11.61" Weight: 10.65 lbs UPC: 0-46221-16017-8
	Master Carton:	Master Carton:
	Dimensions: 15.3"x12.5"x15.0" Weight: 31.97 lbs Quantity: 5 UCC: 20046221180064	Dimensions: 13.98"x10.83"x12.40" Weight: 53.25 lbs Quantity: 5 UCC: 20046221190018
	Units Per Pallet:	Units Per Pallet:
	225 Units	300 Units

NOCO®

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co